


## Catalog No. 54852BEPH

**Description:** TWO HOLE LUG W/PEEP HOLE

**UPC No** 786210232539

**Home > Connectivity & Grounding > Color Keyed / Blackburn > Cable or wire lug**

Copper Two-Hole Lug, Long Barrel, Peep Hole, Max 35kV, Wire Size #6 AWG, 1/4 Inch Bolt Size, 5/8 Inch Hole Spacing, Tin Plated, Die Code 24, Die Color Code Blue

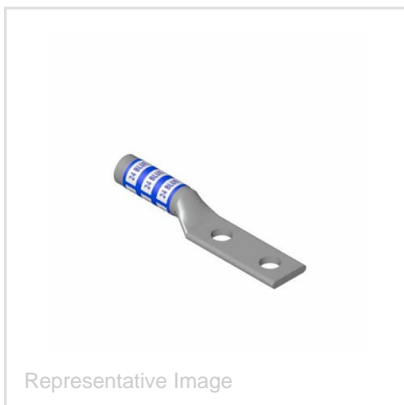

### Descriptors

Category	Cable or wire lug
----------	-------------------

### Specifications

Cable Size	6 AWG
Number Of Holes	2
Voltage Rating	35 kV
Insulation	None
Material	Copper
Color	Blue

### Classifications

Brand Name	Color Keyed / Blackburn
Standard	UL E9809

### Dimensions

Stud Size	1/4 in
-----------	--------

### Compliance and Certifications

RoHS	RoHS3 Compliant
REACH	REACH 247 Compliant
TSCA	TSCA Section 6(h) Compliant

ETIM	EC001051 Tube cable lug for copper conductors
Connecting angle	180° (horizontal)
Slender flange model	N
Insulated	N
With sight-hole	Y

**by ABB**

ETIM	EC001051 Tube cable lug for copper conductors
Material	Copper
Surface protection	Tinned
Number of mounting holes	2
AWG size	6

**Certification/Standard**

CLASS	File Number	Class	CCN	Certificate Number	Library Number
CSA	4503	622302	N/A	N/A	N/A
CSA	7222000	622302	N/A	N/A	N/A
UL	E9809	N/A	N/A	N/A	N/A