

Actuator

61-0019.0



<https://www.eao.com/component/61-0019.0/en/ac...>

Your product:



61-0019.0 Actuator

FRONT

Front dimension:	Ø 18 mm
Front form:	Round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Mounting type:	Panel mounting
-----------------------	----------------

MECHANICAL CHARACTERISTICS

Tightening torque:	Max. 0.5 Nm
Weight:	0.004 kg

AMBIENT CONDITION

IP Protection:	IP40 rear side, according to EN IEC 60529, IP67 front side, according to EN IEC 60529
Operating temperature:	- 25 °C ... + 55 °C
Storage temperature:	- 40 °C ... + 85 °C

CERTIFICATE

REACH:	REACH compliant
RoHS:	RoHS compliant

OTHER


Short Description: Actuator, Ø 18 mm, Round, Black, Plastic

Internal size: Ø 15,8 mm


Housing colour: Black

Housing material: Plastic, according to UL 94 V0, self-extinguishing

Wiring diagrams:

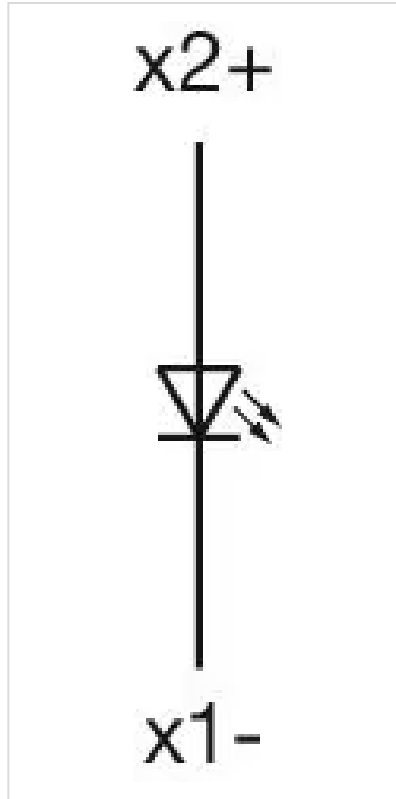


Mounting cut-outs:

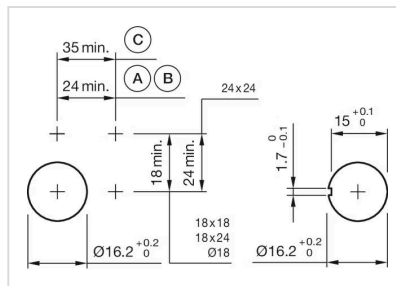

A = Solder/Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal

Dimension drawings:

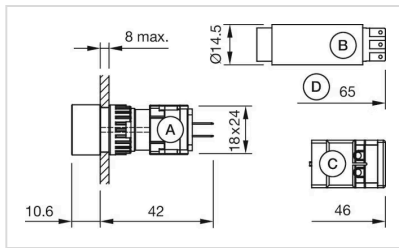

- A = Plug-in terminal 2.8 mm x 0.5 mm
- B = Solder terminal
- C = Screw terminal
- D = Flasher
- E = Slow-make switching element
- F = Snap-action switching element