

[Honeywell.com](#) [Automation & Control Solutions](#)[HOME](#)[ABOUT US](#)[KEY INDUSTRIES SERVED](#)[PRODUCTS & INFORMATION](#)[NEWS & EVENTS](#)[SALES & SUPPORT](#)[LOGIN](#)

## Honeywell Sensing and Control

 
[Search](#)2TL6-1  
(Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL.)**narrow your search**

## Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6165)
- Switches (9781)
- Wireless (45)

## Technology

- Control and Instrumentation (890)
- Electromechanical (9307)
- Magnetic (541)
- Platinum thin film (56)
- Thick Film (1372)
- More...



TL Series Toggle Switch, 2 pole, 3 position, Screw terminal, Tab Lever

Actual product appearance may vary.

[Sales & Service](#) [Distributor Inventory](#) **new products****New Wireless Products**

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.




Wireless Web Site  
WGLA and WPMM  
XYR6000™

[find out more](#)**white papers**

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

**Need help?**[Click here to contact us](#)[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)**Product Specifications**

Circuitry/Operating action

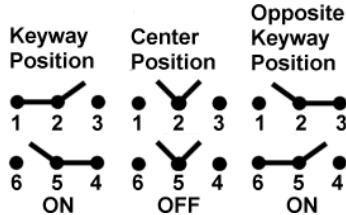**Product Type**

Ampere/Voltage Range (Resistive Load)

Circuitry

Action

Mounting

Termination

Lever Type

UL/CSA

Comment

Availability

UNSPSC Code

UNSPSC Commodity

Series Name

MICRO SWITCH™ Toggle Switch

0.5 A at 250 Vdc, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac, 0.75 A at 115 Vdc

DPDT

3 position

Bushing 15/32 in

Screw

Tab

L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"

Bar actuator with 3 white non-fluorescent buttons

Global

30211908

30211908 Toggle switches

TL

**contacts**

Customer Service  
Technical Support  
Global Sales & Service  
View Site Demo  
Site Comments?

**meet dr. larry**

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.



Meet Dr. Larry

**my links**

[Login to iCOM](#)  
[Login to Rep/AD Portal](#)  
[Login to Digital University](#)

**News Center**

Honeywell Introduces TruStability® NSC Series, Uncompensated / Unamplified Board Mount Pressure Sensors

HONEYWELL EXPANDS ITS LIMITLESS™ PLATFORM WITH THE LAUNCH OF ITS GLOBALLY AVAILABLE INDUSTRIAL WIRELESS RECEIVER

HONEYWELL INTRODUCES MICROPower OMNIPOLAR DIGITAL HALL-EFFECT SENSOR ICS WITH LOW SUPPLY VOLTAGE AND ULTRA LOW TYPICAL CURRENT

HONEYWELL EXTENDS ITS TRUSTABILITY® PRESSURE SENSOR PRODUCT LINE WITH A SINGLE SIDE LIQUID MEDIA OPTION

HONEYWELL ADDS NEW 100° AND 180° ARC CONFIGURATIONS TO ITS SMART POSITION SENSOR PORTFOLIO

HONEYWELL INTRODUCES ITS HAWK™ RESOLVERS 1-INCH SERIES, FULLY HOUSED CONFIGURATION

**MICRO SWITCH Anniversary site**[Terms & Conditions](#) | [Privacy Statement](#) | [Site Map](#)