


Gripping plate; for female and male connectors; 1 part; Pin spacing 3.5 mm; 2-pole; light gray

<https://www.wago.com/2091-1600>



Color: light gray

Similar to illustration

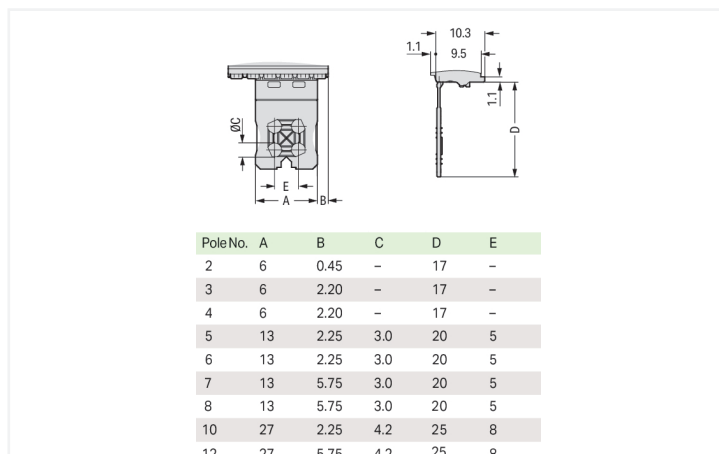

Dimensions in mm

Physical data

Pin spacing	3.5 mm / 0.138 inches
Width	6 mm

Material data

Note (material data)	Information on material specifications can be found here
Color	light gray
Flammability class per UL94	V0
Fire load	0.002 MJ
Weight	0.1 g

Commercial data

Product Group	26 (picoMAX Connectors)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821162735
Customs tariff number	85389099990

Product classification

UNSPSC	39121409
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 8.0	EC002848
ECCN	NO US CLASSIFICATION




Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 2091-1600	↓

Documentation			
Additional Information			
Technical Section	03.04.2019	pdf 2027.26 KB	↓

CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 2091-1600	ZUKEN Portal 2091-1600
↓	↓

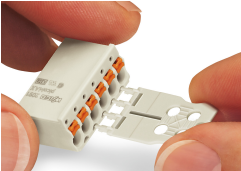Installation Notes	
Strain relief	
	Gripping plates are suitable for factory and field assembly.