


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2017/3/29

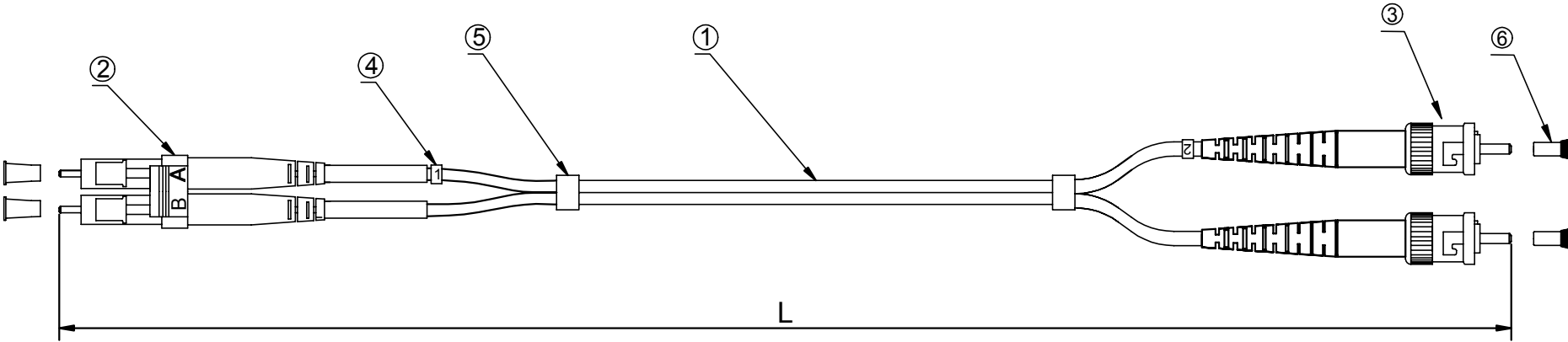

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
913M-2-1-00100	671-445-A	1000±100	Orange
913M-2-1-00200	671-445-B	2000±100	Orange
913M-2-1-00300	671-445-C	3000±100	Orange
913M-2-1-00500	671-445-D	5000±100	Orange
913M-2-1-00700	671-445-E	7000±100	Orange
913M-2-1-01000	671-445-F	10000±100	Orange
913M-2-1-01500	671-445-G	15000±100	Orange
913M-2-1-02000	671-445-H	20000±100	Orange
913M-2-1-02500	671-445-I	25000±100	Orange

NOTES:
Insertion loss < 0.3 dB

6	Dust Cover
5	Shrinkage Tube
4	$\frac{1}{2}$ Code
3	ST MM Connector (Metal housing Red/black boot)
2	LC MM Duplex Connector (Beige housing White boot)
1	2.0mm,Duplex,MM-62.5/125 OM1, PVC, Optical Fiber Cable(Orange)
No.	Description

CnC Tech, LLC Industrial Cable and Connector Technology					
		TITLE	Patch Cord, LC-ST,MM-62.5/125 OM1, Duplex, PVC, orange, 2.0mm, xxM		
UNIT		P/N	above	DRAWN BY	
unless otherwise stated Tolerances mm angular XXX.XX ±0.3 ±2° XX.XX ±0.2 X.XX ±0.1		Customer P/N	913M-2-1-0xxxx	CHECK BY	
		SIZE	SCALE	PAGE	APPROVAL BY
		A4	Free	1/1	