


## Tripp Lite Waber Industrial Power Strip, 6-Outlet, 6 ft. (1.83 m) Cord

MODEL NUMBER: **6SP**

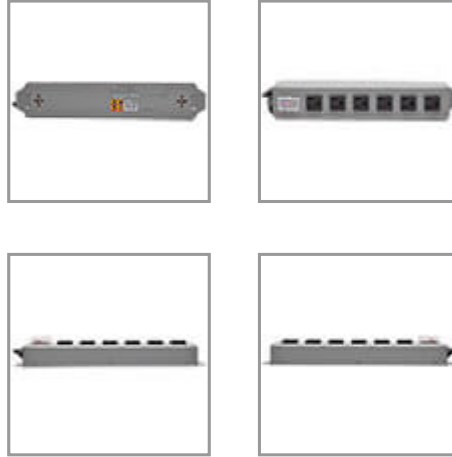

### Highlights

- 6 outlets
- 6-ft. (1.83 m) cord
- 13.7-in. overall length
- Lighted master power switch

### Package Includes

- 6SP Power Strip
- Warranty information
- Instruction manual

### Description

The Waber-by-Tripp Lite 6SP Power Strip offers a convenient method of power distribution in workbench, wallmount or floor mount applications. Includes 6 NEMA 5-15R output receptacles with 1.625 inch center-to-center spacing, 6-ft. (1.83 m) AC line cord and keyhole mounting tabs for installation in a wide variety of applications. Corded, multi-outlet strip reduces cable clutter and enables the connection of multiple electrical devices to a single AC wall socket. Unfiltered electrical pass-through makes 6SP ideal for distributing alternate waveform UPS or generator power. Features rugged all-metal housing, lighted power switch, 15A resettable circuit breaker and attractive blue/gray color scheme. PLUG/OUTLETS - Input: NEMA 5-15P/Output: 6 NEMA 5-15R ELECTRICAL - 120V AC, 50/60Hz, 15A (Requires standard NEMA 5-15R wall receptacle) FORMAT - Corded power distribution strip

### Features

- Multi-outlet power strip offers convenient power distribution in workbench, wallmount or floor mount applications
- Includes 6 NEMA 5-15R output receptacles with 1.625-in. center-to-center outlet spacing
- Lighted power switch
- Keyhole mounting tabs for installation in a wide variety of applications
- UL1363 (USA), cUL (Canada)
- 15A power handling capacity with circuit breaker
- 6-ft. (1.83 m) AC line cord

## Specifications

### OVERVIEW



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

|                                                      |                                                                                |
|------------------------------------------------------|--------------------------------------------------------------------------------|
| UPC Code                                             | 037332103383                                                                   |
| <b>INPUT</b>                                         |                                                                                |
| Nominal Input Voltage(s) Supported                   | 120V AC                                                                        |
| Recommended Electrical Service                       | 15A 120V                                                                       |
| Voltage Compatibility (VAC)                          | 120                                                                            |
| Input Plug Type                                      | NEMA 5-15P                                                                     |
| Input Cord Length (ft.)                              | 6                                                                              |
| Input Cord Length (m)                                | 1.83                                                                           |
| Integrated Cord Clip                                 | No                                                                             |
| <b>OUTPUT</b>                                        |                                                                                |
| Frequency Compatibility                              | 50 / 60 Hz                                                                     |
| Output (Watts)                                       | 1800                                                                           |
| Output Receptacles                                   | (6) 5-15R                                                                      |
| Circuit Breaker (amps)                               | 15                                                                             |
| Transformer Accommodation                            | (2) Yes                                                                        |
| Outlet Orientation                                   | Single row of 6                                                                |
| Right-Angle Outlets                                  | No                                                                             |
| Outlet Spacing                                       | 1.625 in.                                                                      |
| <b>USER INTERFACE, ALERTS &amp; CONTROLS</b>         |                                                                                |
| Switches                                             | Illuminated 2-position switch controls power to all outlets                    |
| <b>PHYSICAL</b>                                      |                                                                                |
| Antimicrobial Coating                                | No                                                                             |
| Color                                                | Gray                                                                           |
| Color (AC Line Cord)                                 | Black                                                                          |
| Integrated Keyhole Mounting Slots                    | Yes (Includes flanges)                                                         |
| Keyhole Slot Mounting Measurement (Center to Center) | Distance between keyhole tabs = 261.92mm; Distance between end tabs = 330.17mm |
| Material of Construction                             | Metal                                                                          |
| Outlets Measurement (Center to Center)               | 41.3mm                                                                         |
| Receptacle Color                                     | Black                                                                          |
| Shipping Dimensions (hwd / cm)                       | 36.83 x 9.14 x 15.49                                                           |
| Shipping Dimensions (hwd / in.)                      | 14.50 x 3.60 x 6.10                                                            |
| Shipping Weight (kg)                                 | 1.01                                                                           |



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

|                                     |                           |
|-------------------------------------|---------------------------|
| Shipping Weight (lbs.)              | 2.22                      |
| Unit Dimensions (hwd / cm)          | 31.75 x 6.35 x 3.8        |
| Unit Dimensions (hwd / in.)         | 12.5 x 2.5 x 1.5          |
| <b>STANDARDS &amp; COMPLIANCE</b>   |                           |
| Canada                              | cUL                       |
| UL1363 (Power Tap)                  | UL1363                    |
| <b>WARRANTY</b>                     |                           |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>