


Part Number : [352841010](#)

Product Description : 2.28mm Tab Wire-to-Wire
Uniconn Housing, Female, 10 Circuits

Series Number : 35284

Status : Obsolete

Product Category : Connector Housings

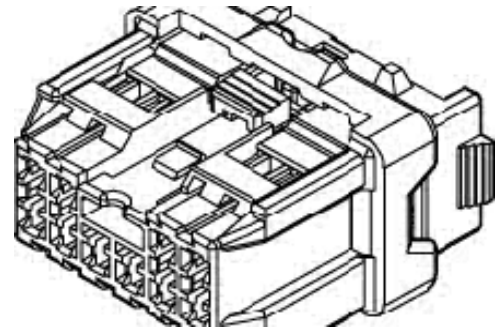

Documents and Resources

Drawings

[352841010_sd.pdf](#)

Specifications

[PK-35284-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Obsolete
Category	Connector Housings
Series	35284
Description	2.28mm Tab Wire-to-Wire Uniconn Housing, Female, 10 Circuits
Application	Power, Wire-to-Wire
Product Name	Uniconn
UPC	800754843171

Physical

Circuits (maximum)	10
Color - Resin	Black, Natural
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	5.330/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.81mm
Temperature Range - Operating	-40° to +80°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
2.28mm Tab Wire-to-Wire Uniconn Housings	<u>35282</u>

Use with Part(s)

Description	Part Number
Tab Terminals	<u>35420</u>
Tab Terminals	<u>35421</u>

This document was generated on May 05, 2026

Obsolete