




+ CONNECTORS

CIRCULAR POWER CONNECTORS

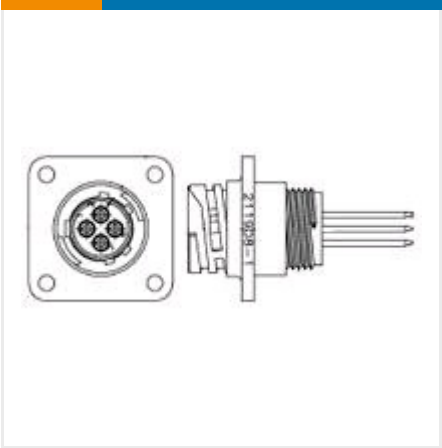

✓ Active

TE CONNECTIVITY (TE)
CPC RCPT, POSTED, SZ 11-4
AMP | CPC

788130-1
TE Internal Number: 788130-1

Not EU RoHS Compliant
Not EU ELV Compliant

Product Type Connector Assembly
Connector System Wire-to-Board, Wire-to-Panel
Number of Positions 4
Housing Type Receptacle
Reverse Gender Reverse

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

RECEPTACLE ASSEMBLY, POSTED, 11-4, REVERSE SEX, CIRCULAR PLASTIC CONNECTOR
PDF
English

CAD Files

Customer View Model
2D_DXF.ZIP
English

Customer View Model
3D_IGS.ZIP
English

Customer View Model

3D_STP.ZIP

English

3D PDF

PDF

English

Product Specifications

Application Specification

Circular Plastic Connectors (CPC)

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

- Product Type** Connector Assembly
- Connector System** Wire-to-Board, Wire-to-Panel
- Housing Type** Receptacle
- Contact Type** Socket
- Shell Type** All Plastic

Configuration Features

- Number of Positions** 4
- Number of Power Positions** 0
- Number of Signal Positions** 4
- Keying** A

Contact Features

- Reverse Gender** Reverse

Mechanical Attachment

- Panel Mount Retention Type** Flange with Mounting Holes
- Connector Mounting Type** Panel
- Mating Alignment** With
- Mating Retention** With
- Panel Mount Retention** With
- Mating Retention Type** Threaded Coupling
- Mating Alignment Type** Keyed

Housing Features

- Shell Size** 11
- UL Flammability Rating** UL 94V-0

Dimensions

Assembly Length (in) 1.759

Usage Conditions

Operating Temperature Range (°C) -55 – 105

Sealed Condition Not Sealed

Fluid Resistance None

Packaging Features

Packaging Quantity 40

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance
PDF