

BWVT008080406R8T00

Search by :

Part Number

Characteristics

Cross reference




MP

?

Closed Magnetic Circuit Type - Automatic Assembly

- Series Pdf
- RoHSREACHCoC
- ICP Report

Product detail	
L(mm) ±	8.0±0.20
W(mm) ±	8.0±0.20
T(mm) ±	3.7~4.2
Inductance(uH)	6.8
Tolerance(±%)	30
Test Frequency	100kHz,1V
RDC(ohm)	0.029
RDC Tolerance(±%)	30
Isat(A)Typ	5.8
Isat(A)Max	5.22
Irms(A)Typ	4.9
Irms(A)Max	4.41
Operating Temperature	− 55℃~ 125℃(Including self - temperature rise)

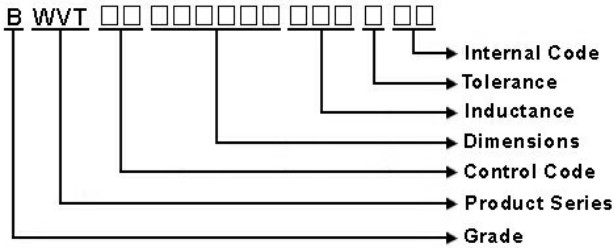

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

[Financial Information](#)

[Corporate governance](#)

[Stakeholder Contacts](#)

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.