


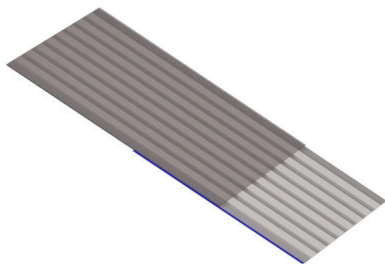

**Part Number :** [152660077](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC  
Jumper, Same Side Contacts (Type A), 76.00mm Cable  
Length, Tin (Sn) Plating, 8 Circuits  
**Series Number :** 15266  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [152660077 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15266-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                           |
|--------------------|-----------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                              |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                              |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                                        |
| REACH SVHC         | Not Contained per D(2025)4165-DC (25 June 2025)                                                           |
| EU RoHS            | Compliant per EU 2015/863                                                                                 |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

---

## Part Details

### General

|              |                                                                                                                     |
|--------------|---------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                              |
| Category     | Flat-Flexible Cable (FFC)                                                                                           |
| Series       | 15266                                                                                                               |
| Description  | 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 76.00mm Cable Length, Tin (Sn) Plating, 8 Circuits |
| Comments     | Contacts on the same side, Type A                                                                                   |
| Product Name | Premo-Flex FFC Jumper                                                                                               |
| UPC          | 884982428409                                                                                                        |

### Electrical

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A   |
| Voltage - Maximum             | 60V AC |

### Physical

|                           |               |
|---------------------------|---------------|
| Cable Length              | 76.00mm       |
| Circuits (Loaded)         | 8             |
| Contact Layout Type       | A (same side) |
| Design Feature            | Flexible      |
| Material - Plating Mating | Tin           |
| Net Weight                | 0.208/g       |
| Packaging Type            | Bag           |
| Pitch - Mating Interface  | 0.50mm        |

|                               |                 |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C  |
| Termination Style             | FFC Connector   |
| Wire/Cable Type               | Flat Flex Cable |
| Wire Size (AWG)               | N/A             |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                                               | Part Number                      |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------|
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 8 Circuits, Tin-Bismuth Plating                                          | <a href="#"><u>525590870</u></a> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 8 Circuits, Tin-Bismuth                                  | <a href="#"><u>527450896</u></a> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 8 Circuits, Tin-Bismuth Plating                       | <a href="#"><u>527460870</u></a> |
| 0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 8 Circuits | <a href="#"><u>781190810</u></a> |
| 0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 8 Circuits   | <a href="#"><u>781270810</u></a> |

---

This document was generated on Sep 10, 2025