




Part Number : [1510760014](#)

Product Description : 11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 4 Circuits

Series Number : 151076

Status : Active

Product Category : Connector Accessories

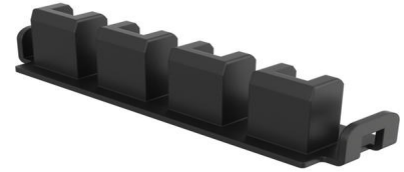

Documents and Resources

Drawings

[1510760014_sd.pdf](#)

[PK-151076-0001-001.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-151053-0000-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Accessories
Series	151076
Description	11.00mm Pitch EXTreme Guardian Receptacle TPA Clip, 4 Circuits
Component Type	Terminal Position Assurance (TPA)
Product Name	EXTreme Guardian
UPC	889056209342

Physical

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Polybutylene Terephthalate (PBT)
Net Weight	2.072/g
Number of Rows	1
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Use with Part(s)

Description	Part Number
11.00mm Pitch EXTreme Guardian Power Receptacle Assembly, PBT, 4 Circuits	<u>1510340014</u>

This document was generated on May 27, 2026