




Part Number : [1600914220](#)

Product Description : MXP120 Backshell, Exit Direction Left, Flange Size NW 7.5, with Cable Tie Access, 4 Circuits

Series Number : 160091

Status : Active

Product Category : Connector Accessories

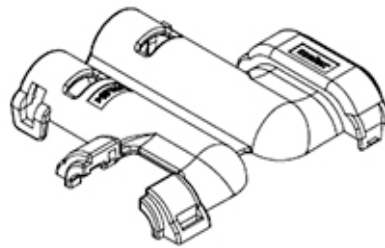

Documents & Resources

Drawings

[1600914220_sd.pdf](#)

[PK-31302-118-001.pdf](#)

3D Models and Design Files

[1600914220_stp.zip](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2020)9139-DC (19 Jan 2021)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Connector Accessories
Series	160091
Description	MXP120 Backshell, Exit Direction Left, Flange Size NW 7.5, with Cable Tie Access, 4 Circuits
Application	Automotive
Component Type	Cover
Product Name	MXP120 Sealed
UPC	889056640695

Physical

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	4.360/g
Packaging Type	Bag
Temperature Range - Operating	-40° to +125°C

Use with Part(s)

Description	Part Number
MXP120 Sealed Receptacle Housings	<u>34900</u>

This document was generated on Jan 15, 2025