


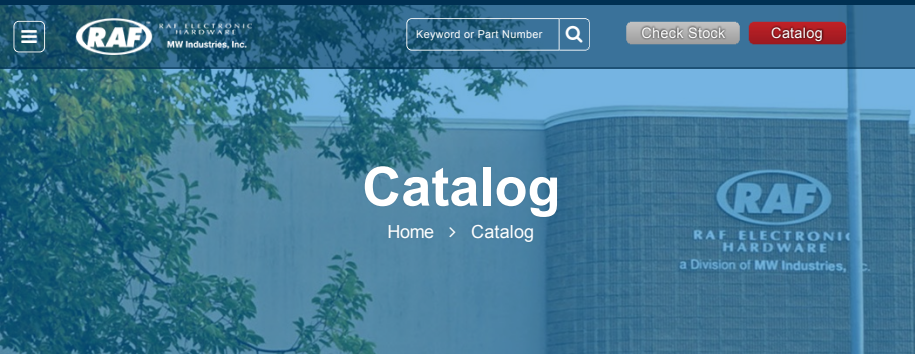

Home > 3040-B-256-B



Swage Standoffs

Model: 3040-B-256-B

Select Finish

-0 No Plate

Select Finish

-0 No Plate

RFQ

Choose a CAD format

Download CAD

View 3D Model

View 2D Drawing

View Spec Sheet

Product Details

These standoffs are made of Brass. They are Round shaped with diameter as 3/16". The thread for this part is 2-56 and length is 3/4".

SWAGE TOOLING		
±.003	S	P
.075	A	1/32
.105	B	1/16
.135	C	3/32
.165	D	1/8
.230	E	3/16
.290	F	1/4

PDF Catalog

RAF_catalog_0096.pdf

Thread	2-56
O.D.	3/16"
Shape	Round
Length (L)	3/4"
Material	Brass
RoHS	Yes
Shank Length	0.105"
Board Thickness	1/16"
Shank Diameter	0.139"
Thread Clearance	0.108"
Finish	-0 No Plate

RAF ELECTRONIC
HARDWARE

In 2008, RAF joined with MW Industries Inc., www.mw-ind.com, to become the nation's leading supplier of electronic hardware components to a variety of industries, including computers, telecommunications, medical, entertainment and military/aerospace.

Technical Information

- Electronic Hardware Components
- Engineering Data
- Capabilities Brochure
- Services
- Distributors

Company

- RAF Quality Management
- Industry Links
- What's New
- News
- About
- Contact
- Careers

Contact Us

95 Silvermine Rd.
Seymour CT 06483

Find Us

