



Search by part # or keyword

Products

Industries &
Solutions

Resources

TE Store


Sign In



[Harnessing](#) > [Heat Shrink Components](#) > [Feedthroughs & Cable Entry Seals](#)

207W234-3-01/42-0

207W234-3-01/42-0

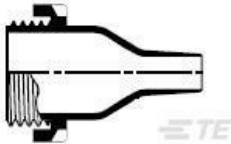

Raychem

TE Internal #: **878127-000**
TE Internal Description: **207W234-3-01/42-0**
Alias #: **2-1196833-5**

Product Type : **Cable Entry
Seals/Feedthroughs**
Threaded End Inside Diameter : **30.1 mm [27.9 in]**
Nut Type : **B**
Power Cable Accessory : **No**
Color : **Black**

[Similar Products](#)

Compatible Parts & Tooling

We are here to help!
Get in touch with our product experts.



CHAT WITH US



EMAIL US



CALL US

Documents

Features

Product Compliance

Product Drawings

207W234-3-01/42-0

207W234-3-01/42-0 English

Datasheets & Catalog Pages

1654025_Sec4_-3

ENG_CS_1654025_Sec4_-3_0313.pdf English

Product Environmental Compliance

Safety Datasheet

DUT_MSDS_RAY3143-EC-DUT_2014-06-11_3143ECN.pdf Dutch

ENG_MSDS_RAY3143-EC-ENG_2014-06-11_3143ECE.pdf English

Safety Datasheet

FRE_MSDS_RAY3143-EC-FRE_2014-06-11_3143ECF.pdf French

Safety Datasheet

GER_MSDS_RAY3143-EC-GER_2014-06-11_3143ECD.pdf German

Safety Datasheet

ITA_MSDS_RAY3143-EC-ITA_2014-06-11_3143ECI.pdf Italian

Safety Datasheet

SPA_MSDS_RAY3143-EC-SPA_2014-06-11_3143ECS.pdf Spanish

Safety Datasheet

SWE_MSDS_RAY3143-EC-SWE_2014-06-11_3143ECW.pdf Swedish

Safety Datasheet

Feedback

📄 [ENG_MSDS_RAY3143-US-ENG_B.pdf](#) English

Safety Datasheet

📄 [FRE_MSDS_SDS0190-EC-FRE_2014-04-10.pdf](#)
French

Safety Datasheet

📄 [ITA_MSDS_SDS0190-EC-ITA_2014-04-10.pdf](#)
Italian

Safety Datasheet

📄 [NOR_MSDS_SDS0190-EC-NOR_2014-04-10.pdf](#) Norwegian

Safety Datasheet

📄 [DAN_MSDS_SDS0190-EC-DAN_2014-04-10.pdf](#) Danish

Safety Datasheet

📄 [ENG_MSDS_SDS0190-EC-ENG_2014-04-10.pdf](#)
English

Safety Datasheet

📄 [GER_MSDS_SDS0190-EC-GER_2014-04-10.pdf](#)
German

Safety Datasheet

📄 [SPA_MSDS_SDS0190-EC-SPA_2014-04-10.pdf](#)
Spanish

Safety Datasheet

📄 [SWE_MSDS_SDS0190-EC-SWE_2014-02-21_SDS190ECW.pdf](#) Swedish

Safety Datasheet

📄 [DUT_MSDS_SDS0190-EC-DUT_2014-04-10.pdf](#)
Dutch

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type : **Cable Entry Seals/Feedthroughs**
Size Code : **34**
Included O-Ring : **No**

Body Features

Material Code : **3**
Nut Type : **B**
Color : **Black**
Material : **Modified Polyolefin**
Pliancy : **Semi-Rigid**
Adhesive Pre-Coat : **Yes**

Mechanical Attachment

Mounting Hole Diameter : **47 mm [1.85 in]**

Dimensions

Threaded End Inside Diameter : **30.1 mm [27.9 in]**
Expanded Inside Diameter (Min) : **26.4 mm [1.04 in]**
Recovered Inside Diameter (Max) (mm): **12, 12 – .47**
Recovered Inside Diameter (Max) (in): **.47**
Recovered Wall Thickness (Nominal) : **2.03 mm [.08 in]**
Length : **87 mm [3.42 in]**



Usage Conditions	Resistant To : Abrasion, Fluids, Mechanical Damage, Strain Resistance Properties : Immersion Protection
Operation/Application	Power Cable Accessory : No
Industry Standards	Government Qualified : No
Other	Adhesive Type : General Purpose Pre-Coat Adhesive Adhesive Code : 42
EU RoHS Directive 2011/65/EU <i>This declaration covers EU Directive 2011/65/EU incl. Delegated Directive 2015/863/EU. The restrictions under 2015/863/EU apply as of 22 July 2021 for EEE categories 8 (medical devices) and 9 (monitoring and control equipment).</i>	
EU ELV Directive 2000/53/EC	
China RoHS 2 Directive MIIT Order No 32, 2016	
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2019 (197) Candidate List Declared Against: JAN 2019 (197)
Halogen Content	
Solder Process Capability	Not applicable for solder process capability
Statement of Compliance	Statement of Compliance pdf
Compliance Documents	There may be Environmental Compliance related documents on the DOCUMENTATION Tab
Disclaimer	This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP and 0.01% for cadmium, or qualify for an

exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Products with Similar Specs

[View All Similar Products](#)


THIS PRODUCT

TOP RESULTS ?

FEEDTHROUGHS

[207W234-3-01/42-0](#)

207W234-3-01/42-0

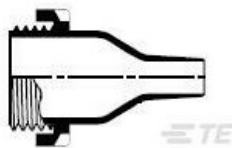

In-Stock

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **30.1 mm**

Nut Type : **B**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

[207W234-3/42-0](#)

207W234-3/42-0

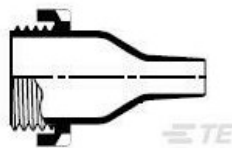

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **30.1 mm**

Nut Type : **A**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

[207W234-3-01/86-0](#)

207W234-3-01/86-0

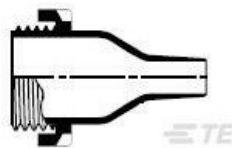

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **30.1 mm**

Nut Type : **B**


Power Cable Accessory : **No**

Color : **Black**

FEEDTHROUGHS

[207W234-25-01/86-0](#)

207W234-25-01/86-0

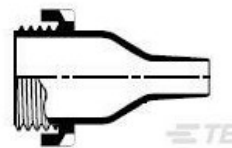

Non-Stocked

Product Type : **Cable Entry Seals/Feedthroughs**

Threaded End Inside Diameter : **30.1 mm**

Nut Type : **B**

Power Cable Accessory : **No**

Color : **Black**

[ABOUT TE CONNECTIVITY](#)

[FOR PARTNERS](#)

[SUPPORT](#)

[CALL US](#)

[LIVE CHAT](#)

[UNITED STATES \(EN\)](#)