


C-Filter D-Sub Connector
Solder pin angled .370" (9.40 mm)
with mounting-,
grounding bracket
and threaded lock

This right angle version incorporates a front locking bolt. The hexlocking bolts that are normally used are no longer required. The locking bolt is available with UNC 4-40 or M 3 internal thread.



(click on the schematic(s) for a more detailed view)

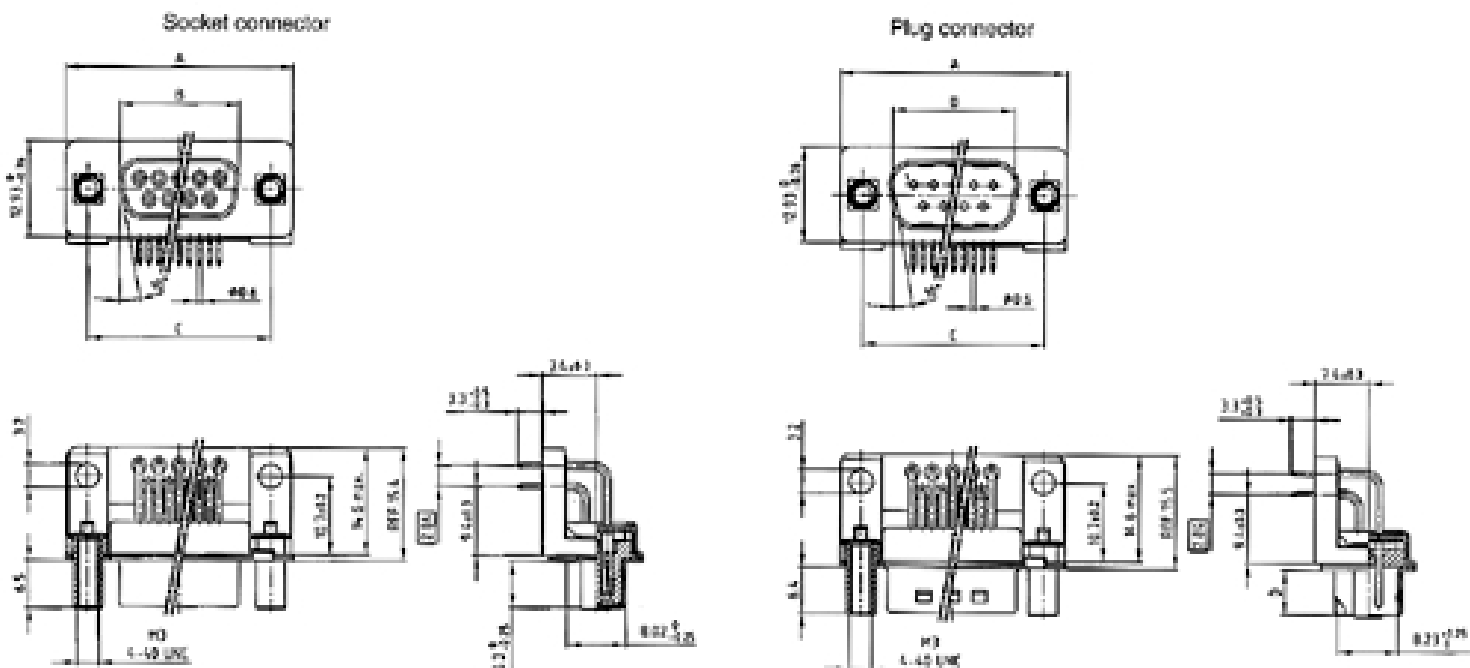

Socket Connector			
No. of pos.	A -0,76	B -0,25	C
9	31,19	16,46	25,00 ^{+0,12} _{-0,13}
15	39,52	24,79	33,30 ^{+0,15} _{-0,10}
25	53,42	38,50	47,04 ^{±0,13}
37	69,70	54,96	63,50 ^{±0,13}

Plug Connector				
No. of pos.	A -0,76	B +0,25	C	D -0,30
9	31,19	16,79	25,00 ^{+0,12} _{-0,13}	6,12
15	39,52	25,12	33,30 ^{+0,15} _{-0,10}	6,12
25	53,42	38,84	47,04 ^{±0,13}	5,99
37	69,70	55,30	63,50 ^{±0,13}	5,99

Part Numbers

No. of Pos.		Socket connector - Solder pin angled			
		180 pF	370 pF	830 pF	1300 pF
9	thread UNC 4-40	242 A 16900 X	242 A 11330 X	242 A 11410 X	242 A 11370 X
15		242 A 16910 X	242 A 11340 X	242 A 11420 X	242 A 11380 X
25		242 A 16920 X	242 A 11350 X	242 A 11430 X	242 A 11390 X
37		242 A 16930 X	242 A 11360 X	242 A 11440 X	242 A 11400 X
9	thread M 3	242 A 16940 X	242 A 11450 X	242 A 11530 X	242 A 11490 X
15		242 A 16950 X	242 A 11460 X	242 A 11540 X	242 A 11500 X
25		242 A 16960 X	242 A 11470 X	242 A 11550 X	242 A 11510 X
37		242 A 16070 X	242 A 11480 X	242 A 11560 X	242 A 11520 X

No. of Pos.		Plug connector Solder pin angled			
		180 pF	370 pF	830 pF	1300 pF
9	thread UNC 4-40	241 A 19520 X	241 A 11330 X	241 A 11410 X	241 A 11370 X
15		241 A 19530 X	241 A 11340 X	241 A 11420 X	241 A 11380 X
25		241 A 19540 X	241 A 11350 X	241 A 11430 X	241 A 11390 X
37		241 A 19550 X	241 A 11360 X	241 A 11440 X	241 A 11400 X
9	thread M 3	241 A 19560 X	241 A 11450 X	241 A 11530 X	241 A 11490 X
15		241 A 19570 X	241 A 11460 X	241 A 11540 X	241 A 11500 X
25		241 A 19580X	241 A 11470 X	241 A 11550 X	241 A 11510 X
37		241 A 19590 X	241 A 11480 X	241 A 11560 X	241 A 11520 X