

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2072350100

Status:


Active

Overview:

Antennas

Description:

824MHz-2170MHz Cellular Flexible Antenna, 100.00mm Cable Length

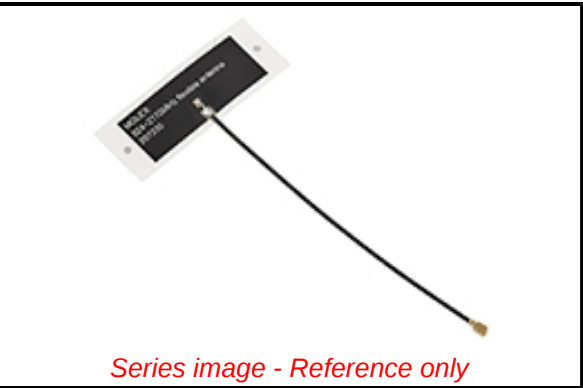

Documents:	
Drawing (PDF)	Packaging Specification 2072350100-PK (PDF)
Product Specification 2072350100-PS (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 2072350100-AS (PDF)	Product Literature (PDF)

General	
Product Family	Antennas
Series	207235
Component Type	Stand Alone Antenna with Cable
Mates With	73412-0110 Microcoaxial RF, 50 Ohm
Overview	Antennas
Product Literature Order No	987651-7811
Product Name	Cellular Flexible Antenna
Protocol	Cellular
Type	Cellular Antenna
UPC	191128861267
Physical	
Cable Length	100.00mm
Length	40.40mm
Mounting Style	Adhesive
Net Weight	0.771/g
Packaging Type	PET Film
Polarization	Linear
Radiation Pattern	Omnidirectional
Thickness	0.10mm
Width	15.40mm
Electrical	
Band#1 F_End (MHz)	960
Band#1 F_Start (MHz)	824
Band#2 F_End (MHz)	2170
Band#2 F_Start (MHz)	1710
Electrical Connectivity	Cable
Peak Gain (dBi)	0 @ 824M, 4.3 @ 1710M
Return Loss - S11 (dB)	< -4, < -6
Total Efficiency	>30% @ 824M, >60% @ 1710M
Material Info	
Reference - Drawing Numbers	
Application Specification	2072350100-AS
Packaging Specification	2072350100-PK
Product Specification	2072350100-PS
Sales Drawing	2072350100-SD

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

ED/61/2018 (27 June

2018)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

207235 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION