




+ CONNECTORS
HEAT SINKS

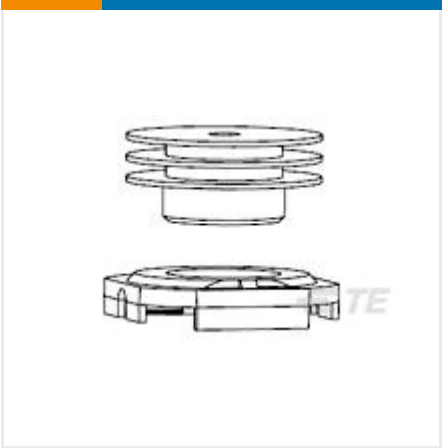

✓ Active

TE CONNECTIVITY (TE)
HTS779-U=25MM HS ASSY ULTEM CL

Thermal Solutions | CL , HS

6-1542004-6
TE Internal Number: 6-1542004-6
Alias ID: HTS779-U

EU RoHS Compliant with Exemptions
EU ELV Compliant with Exemptions

Product Type Heat Sink
Device Type BGA
Fin Style Radial
Number of Fins 3
Power (W) 10, 15, 5

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings
25mm HS ASS'Y (HTS779-U)
PDF
English

CAD Files
3D PDF
PDF
3D

Customer View Model
2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Heat Sink
Device Type BGA
Accessory Type Clip

Configuration Features

Number of Fins 3
Fan Type No Fan

Electrical Characteristics

Power (W) 10, 15, 5

Body Features

Fin Style Radial
Material Die Cast Aluminum
Plating Material Black Anodized

Dimensions

Height 11.23 mm [.442 in]
Diameter 25.4 mm [1 in]
Width (in) 1

Usage Conditions

Thermal Resistance (°C) 1.2, 1.38, 1.43

Operation/Application

For Use With BGA Semiconductor Packages
I/O Pluggable No

Industry Standards

UL Flammability Rating UL 94V-0

Other

Comment Mounting clip does not increase overall heat sink height.

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF

