




TOP VIEW

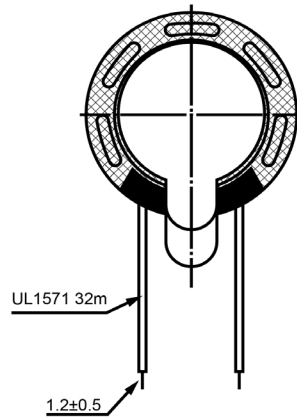

SIDE VIEW

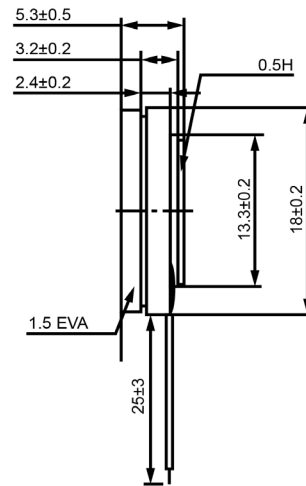

BOTTOM VIEW

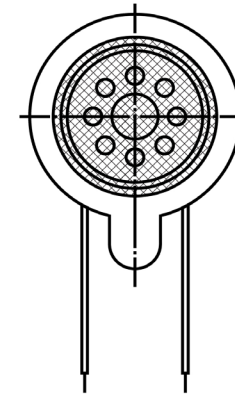

Specifications

Description	Value	Unit
Shape	Round	
Resonant Frequency	850	(Hz)
Frequency Range	850 ~ 20,000	(Hz)
SPL @ 10cm	89	(dBA)
Impedance	8	(Ohm)
Cone Material	Mylar	
Nominal Power	0.8	(W)
Max Power	1	(W)
Mount Type	Flush Mount	
Operating Temperature	-25 ~ +60	°C
Storage Temperature	-25 ~ +60	°C
Weight	1.65	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
</					

Micro Speaker

SM180808-2