


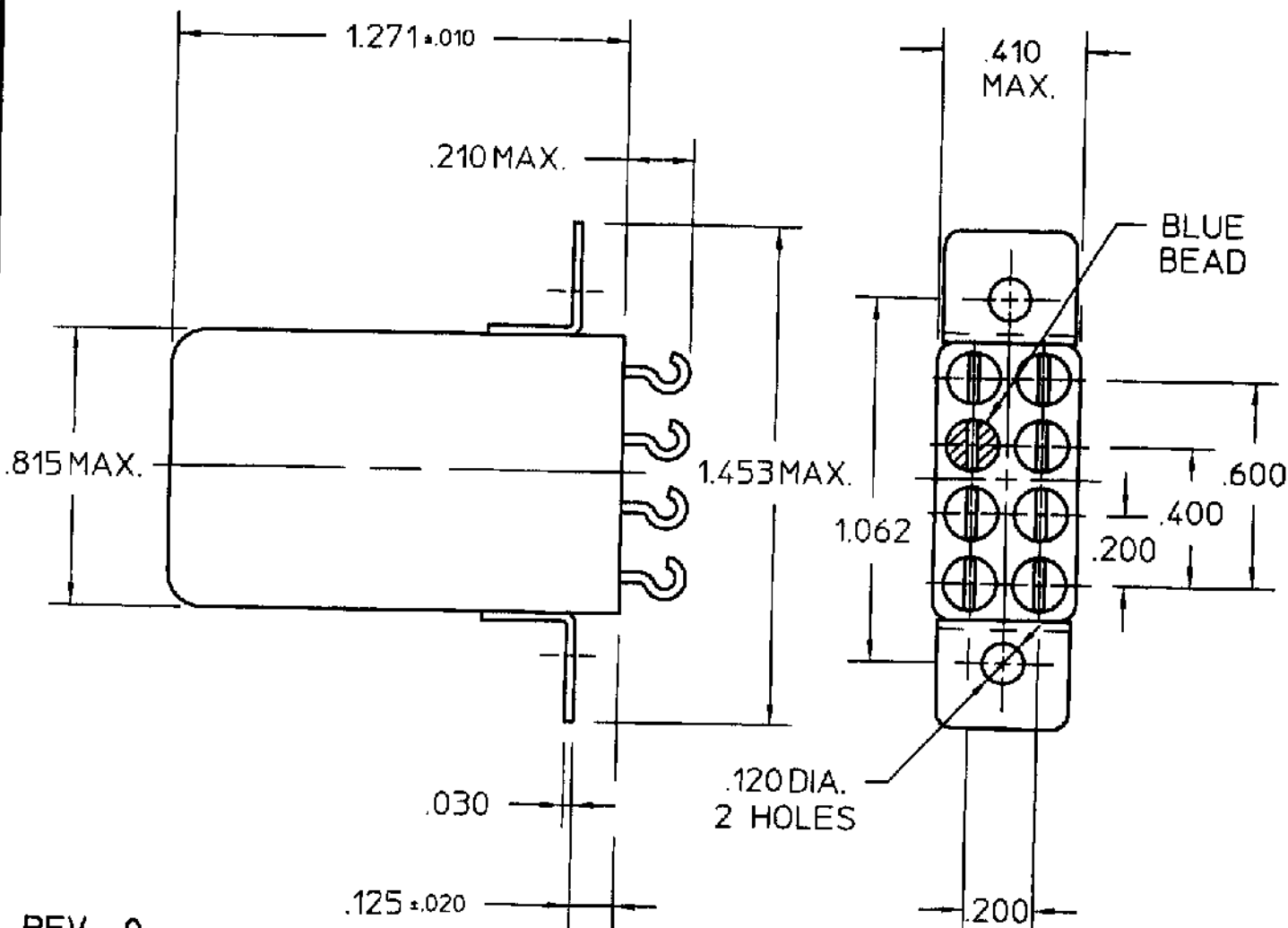

REV. 0  
DCO 170339


COIL: @ 25°C  
RESISTANCE 5000 OHMS ± 10%  
NOMINAL VOLTAGE 6.0 mADC  
MUST OPERATE 2.8 mADC  
MUST RELEASE 1.4 mADC MAX, 0.3 mADC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
SHOCK 100 g's 6 MS DURATION  
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.  
RELEASE TIME 10 MS MAX.  
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

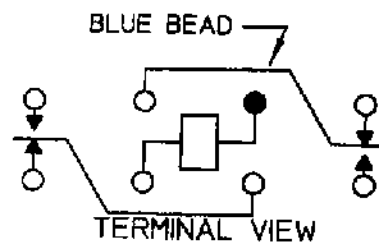

CONTACT RATING: 2 AMPS 28 VDC  
RESISTIVE 100,000 OPERATIONS

DR. PBB 12/6/00 CK. TLG 12-6-00

**CII Technologies**  
advanced control electronic solutions

CUST. QPL  
CUST. NO. M5757/13-090 REV.

3SAT RELAY

3SAT1307A2