


FSN-24.25Z-25 Product Details

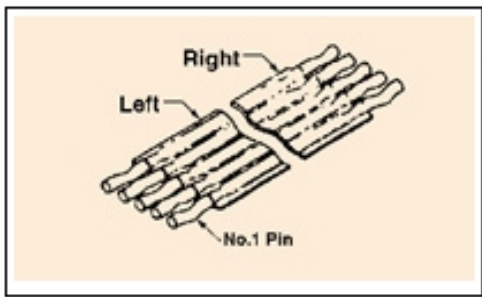

FSN-24.25Z-25

TE Part Number: 1-1437145-4

Active

Add to Part List

FLEXSTRIP® Jumpers

Converted to EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- 2.54 mm Centerline
- Nomex Insulation Material
- Insulation Length = 107.95 mm
- Pin Arrangement (Left) = Z
- Pin Arrangement (Right) = Z

View all Features

 |

Find Similar Products

Live Product Chat

Quick Links

Check Pricing & Availability

Search for Tooling

Product Feature Selector

Contact Us About This Product

Request Samples

NEW!

Documentation & Additional Information	
Product Drawings: JUMPER, NOMEX FLEXSTRIP 25 CONDUCTOR (PDF, English) Catalog Pages/Data Sheets: - None Available Product Specifications: - None Available Application Specifications: - None Available Instruction Sheets: - None Available CAD Files: - None Available List all Documents	Additional Information: Product Line Information Additional Product Images: Product View Product View Related Products: Tooling

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: Insulation Material = Nomex Number of Conductors = 25 Electrical Characteristics: - Current Rating (Amps.) = 3 - Impedance (Ω) = 107 - Voltage Rating (VAC) = 300 Body Related Features: Centerline (mm [in]) = 2.54 [0.100] Insulation Length (mm [in]) = 107.95 [4.250]	Configuration Related Features: Pin Arrangement (Left) = Z Pin Arrangement (Right) = Z Industry Standards: RoHS/ELV Compliance = RoHS compliant, ELV compliant Lead Free Solder Processes = Wave solder capable to 240°C, Wave solder capable to 260° C, Wave solder capable to 265°C - RoHS/ELV Compliance History = Converted to comply with RoHS directive Conditions for Usage: - Operating Temperature (°C [°F]) = -40 – +125 [-40 – +257] Other: - Brand = Tyco Electronics