

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

51048-1000

Status:

Active

Description:

2.00mm Pitch Cable Holder, Vertical, Low Profile, for Ribbon Cable, 10 Circuits

Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Component Type

Glow-Wire Compliant

Product Name

UPC

Ribbon Cable / Wire Trap Connectors

51048

One Piece

No

Board-In, Cable Holder

800753574793

Physical

Circuits (Loaded)

Color - Resin

Entry Angle

Lock to Mating Part

Material - Plating Mating

Material - Resin

Net Weight

Number of Rows

PCB Retention

PCB Thickness - Recommended

Packaging Type

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Polarized to PCB

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Wire Insulation Diameter

Wire Size AWG

Wire/Cable Type

10

Natural

Vertical

None

N/A

Nylon

216.500/mg

1

Yes

1.60mm

Bag

2.00mm

2.00mm

N/A

No

No

No

-40°C to +105°C

1.60mm max.

26

Ribbon Cable

Electrical

Current - Maximum per Contact

Voltage - Maximum

N/A

N/A

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-51048-001

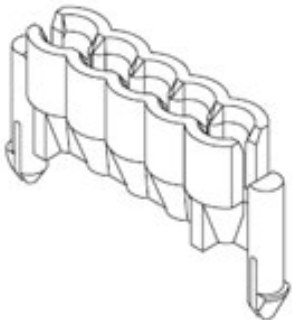


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

51048Series

Mates With

N/A

Use With

Topcoated Ribbon Cable

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION