


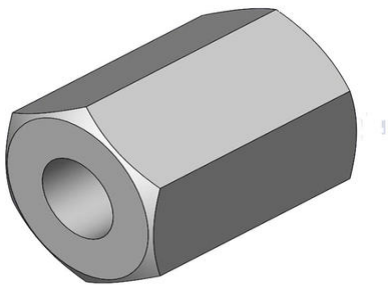

Part Number : [1731120071](#)
Product Description : FCT Female Standoff Hex Nut for Cable to Cable Connections, #4-40 Thread, 6.20mm Height, Zinc-plated Steel
Series Number : 173112
Status : Active
Product Category : D-Sub Accessories
Engineering Part Number : F1066



Documents and Resources

Drawings

[1731120071_sd.pdf](#)

Specifications

[1731120005-PK-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	D-Sub Accessories
Series	173112
Description	FCT Female Standoff Hex Nut for Cable to Cable Connections, #4-40 Thread, 6.20mm Height, Zinc-plated Steel
IP Rating	N/A
Magnetic	Yes
Product Name	FCT Products
Type	Backshell
UPC	889056323918

Physical

Accessory Type	Female Standoff Nut
Material - Body	Steel
Net Weight	0.600/g
Packaging Type	Bag
Thread Size	4-40 UNC
Thread Type	Standard