
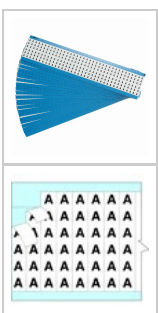


[Labels](#) / [Labels by Application](#) / [Wire and Cable Labels](#) / [Wire and Cable Label Cards](#) /

Alphabetical Vinyl Cloth Upper Case Wire Marking Cards

Alphabetical Vinyl Cloth Upper Case Wire Marking Cards

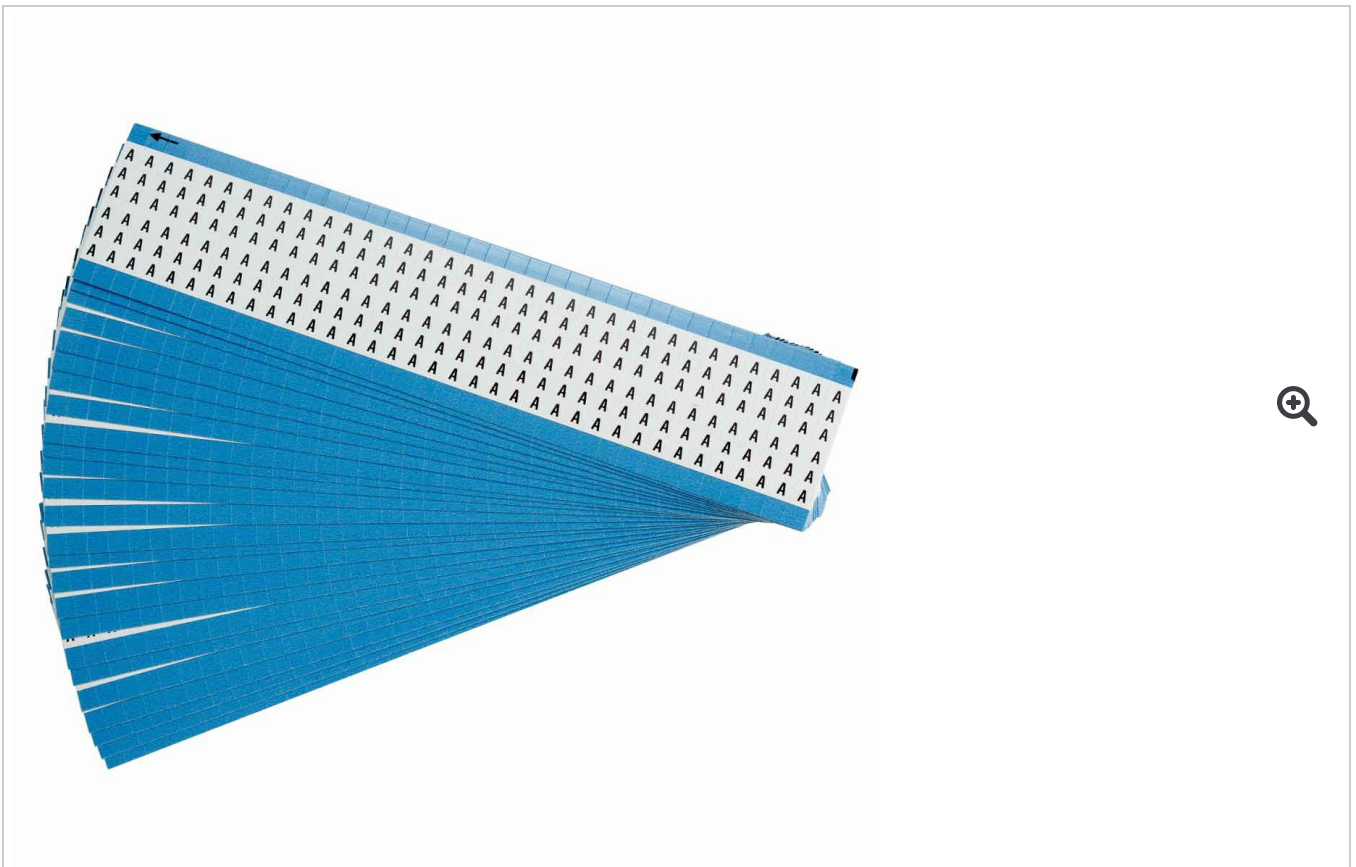

Product Highlights:

Dimensions:

1.5 in H

Material:

Vinyl Cloth

Color:

Black on White

Choose your options: [Reset Options](#)

1 Text Legend

A

Part Number:

WM-A-PK



[View All Options](#)

ADD TO CART

+

-



[Add To Favorites](#)

Free wire and cable ID sample pack



Download guide



Request product certification



Overview

B-500 Repositionable Vinyl Cloth wire markers from Brady® are perfect for your general wire marking needs.

- Card-mounted wire markers allow for quick, on-the-spot wire marking
- Brady B-500 Repositionable Vinyl Cloth holds tightly to surfaces but allows item to be repositioned with ease if necessary
- Excellent flexibility for wrapping around curved surfaces
- Withstands moderate heat, oil, water and dirt

Labeling Cables and Wires

How to select a wire marker for your next job

5
CONSIDERATIONS

Specifications

Key Characteristics		224
	Product Number	112327
	UPC	662820913597
	UOM	Pack of 25 Cards
	Quantity per Card or Sheet	36
	Cards or Sheets per Pack	25
	Brand Name	Brady®
		Mexico
		5906.99.1000
		EAR99

Dimensions	Dimensions	1.5 in H
	Height	1.5 in
	Thickness	0.0088 in

Material Characteristics		B-500 (View Technical Data Sheet)
		Vinyl Cloth
	Label Properties	Repositionable Labels
	Adhesive Type	Repositionable Rubber
	Finish	Matte
	Color	Black on White
	Resistance Properties	Abrasion-Resistant, Corrosion-Resistant, Humidity-Resistant, Oil-Resistant, UV-Resistant, Water-Resistant, Weather-Resistant
	Minimum Service Temperature °F	-40 °F
	Maximum Service Temperature °F	176 °F
	Minimum Application Temperature °F	50 °F
	Compatible Surface Types	Low Surface Energy

Product Features		Wire and Cable Labeling
	Label/Media Format	Die-Cut on Cards

Preprinted Information	Text Legend	A
Compliance		39131507
		7690004501518

Corporate

[About](#)
[Careers](#)
[Investors](#)
[Do Not Sell My Personal Info](#)
[Privacy Policy](#)
[Terms and Conditions](#)
[ISO Certificates](#)

Other Brady Sites

[Distributor Portal](#)
[International Sites](#)
[Brand Protection Solutions](#)

Help

[Contact Us](#)
[Customer & Technical Support](#)
[Resource Center](#)
[Searchable Support Articles](#)
[Certificate Request](#)
[Website Feedback](#)

Contact

6555 W. Good Hope Rd
Milwaukee, WI 53223

Phone: [888-250-3082](tel:888-250-3082)
Hours: 7:00am–5:00pm CT
Monday–Friday

Brady (NYSE:BRC) is a manufacturer of
complete solutions that identify and

We use cookies to ensure you get the best
experience on our website. [Learn More.](#)

GOT IT!