


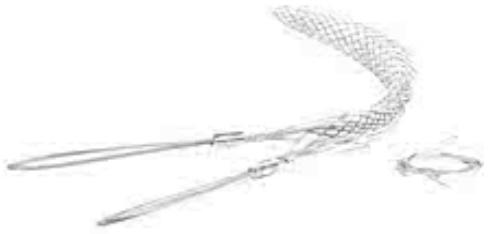

Part Number : 1300940466

Product Description : Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 2140.96kg (4720 lbs)



Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 35441

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 2140.96kg (4720 lbs)
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835441

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	2140.96kg (4720 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	25.40-31.50mm (1.000-1.240")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.737m (29.00")
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A

This document was generated on Sep 13, 2025