

Extended Handle Accessories



LK10

DOOR INTERLOCK HANDLES

(padlockable with up to three 1/4" padlocks)

LK10 (Y/R) UL:


- Single hole mounting (22.5 mm)

LK11 (Y/R) U:


- Retention mechanism (only rotates 90° from off to on, keeps handle in off position while cabinet door is open)



Example of handle with 1/4" padlocks.

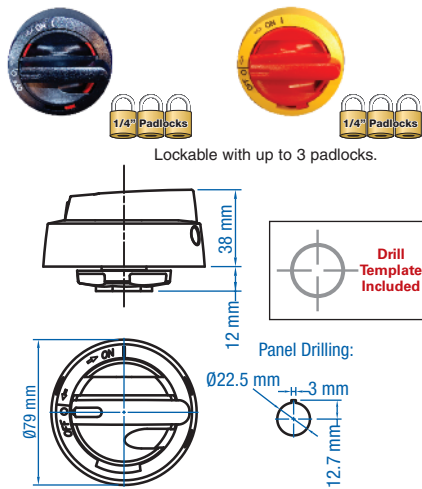

LK11

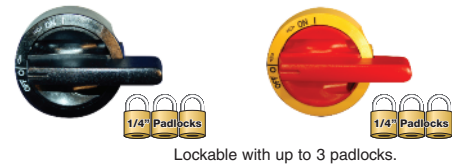

Cat. No.

Environmental Rating (UL) (IEC)

Color

LK10 UL

UL Type 4X
IP66

Black

LK10 Y/R UL

UL Type 4X
IP66

Yellow/Red

LK11 U

UL Type 4X
IP67

Black



LK11 Y/R U

UL Type 4X
IP67

Yellow/Red

DEFEATABLE MECHANISM - OPERATING INSTRUCTIONS

The defearer mechanism allows a screwdriver to be inserted to release the lock and open the door with the mechanism in the ON position.

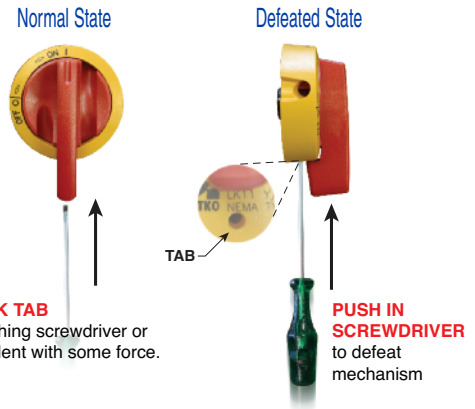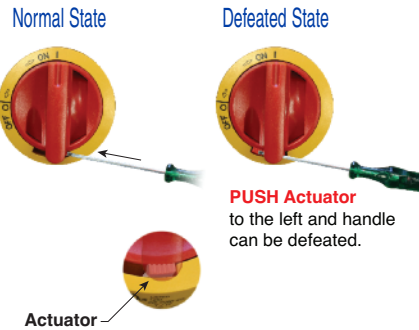


Warning: The defearer mechanism should only be used by a trained professional.

Note: After tab is broken, NEMA Type 4X rating will be lost.

DOOR INTERLOCK SHAFT

The steel shaft ensures reliable operation even in the toughest conditions.

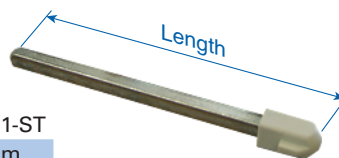

Cat. No.

Length (L)

Material

L100 AD11-ST

100 mm

Steel

L200 AD11-ST

200 mm


Steel

L300AD11-ST

300 mm

Steel

SHAFT LENGTH CUTTING GUIDELINE

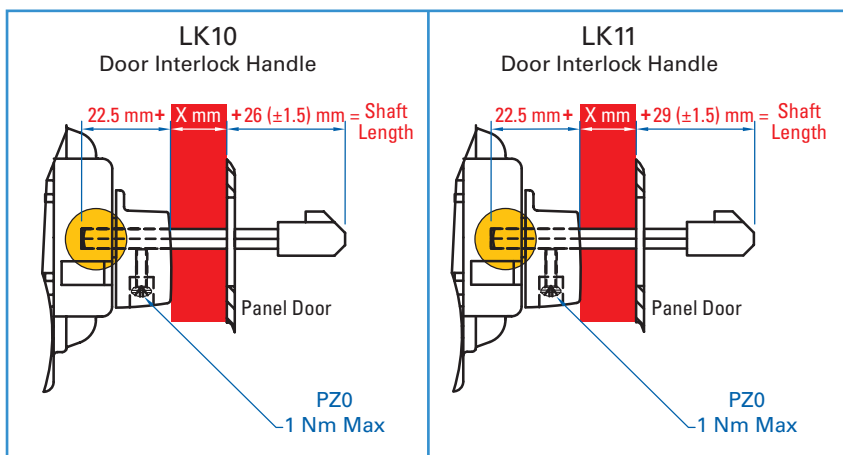

SHAFT CUTTING RECOMMENDATIONS

