

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0687840002

Status:

Active

Overview:

Micro USB

Description:

USB Shielded I/O Cable Assembly, USB A-to-Micro-USB B, 1.50m Length, Black, Lead-Free

Documents:

Drawing (PDF)

Packaging Specification PK-68784-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Cable Assemblies

Series

68784

Assembly Configuration

Dual Ended Connectors

Connector to Connector

USB Type A-to-Micro-USB Type B

Overview

Micro USB

Product Name

Micro-USB, USB

UPC

883906173746

Physical

Cable Length

1.50m

Circuits (Loaded)

4, 5

Color - Resin

Black

Gender

Male-Male

Lock to Mating Part

Yes

Material - Metal

Copper Alloy

Material - Plating Mating

Nickel

Material - Plating Termination

Gold

Material - Resin

PVC

Net Weight

37.700/g

Number of Rows

1

Packaging Type

Bag

Single Ended

No

Waterproof / Dustproof

No

Wire Size AWG

28

Wire/Cable Type

Round

Electrical

Current - Maximum per Contact

1.8A, 1.0A

Impedance

90Ω

Shield Type

Full Shield

Shielded

Yes

Voltage - Maximum

30V AC

Material Info


Reference - Drawing Numbers

Packaging Specification

SD-68784-001, SD-68784-001-001

Sales Drawing

PK-68784-001-001

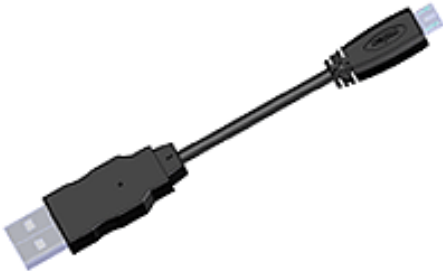

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Compliant

Not Contained

Search Parts in this Series

68784 Series

Mates With

Micro-USB B-type Receptacles

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION