

Part Number : 1552200115


Product Description : Flamar Control Cable, WSOR Jacket, Unshielded, 4 Circuits, 0.50mm² with Green-Yellow Ground / 21 AWG with Green-Yellow Ground, 5.90mm (.232") Diameter, 300.0m (984.25') Length, Black

Series Number : 155220

Status : Active

Product Category : Industrial Cable

Engineering Number : 3X100M

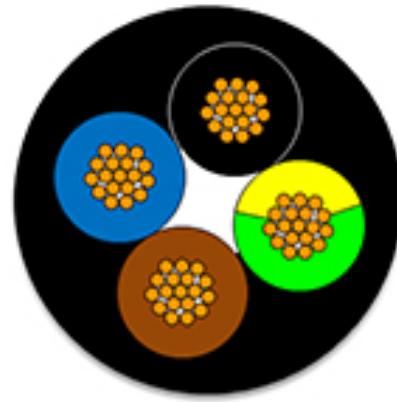

Documents & Resources

Specifications

Product Specification 1552200001-P1E.pdf

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Industrial Cable
Series	155220
Description	Flamar Control Cable, WSOR Jacket, Unshielded, 4 Circuits, 0.50mm ² with Green-Yellow Ground / 21 AWG with Green-Yellow Ground, 5.90mm (.232") Diameter, 300.0m (984.25') Length, Black
Comments	3 reels of 100.0m each
Geographic Area	Global
Product Family	Flamar Standard and Custom Cables for Industrial Automation
Product Name	Flamar, Signal and Control
UPC	889056458894

Agency

UL	E172949
----	---------

Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	600V

Physical

Bending Radius - Minimum	> 7.5xOD
Cable Length	300.0m
Circuits (Loaded)	4
Color - Cable Jacket	Black
Insulation	TPE
Material - Outer Jacket	WSOR
Net Weight	0.050/kg
Outer Jacket Diameter	5.90mm
Packaging Type	Reel

Temperature Range - Operating	-25° to +80°C
Wire/Cable Type	UL AWM 21215 / CSA
Wire Size (AWG)	21
Wire Size mm ²	0.50

Use with Part(s)

Description	Part Number
mPm DIN Valve Connectors	<u>121201</u>
mPm DIN Valve Connectors	<u>121202</u>
mPm DIN Valve Connectors	<u>121205</u>
mPm DIN Valve Connectors	<u>121207</u>
mPm DIN Valve Connectors	<u>121208</u>
mPm DIN Valve Connectors	<u>121211</u>
Micro-Change (M12) Field Attachable Connectors	<u>120071</u>
Ultra-Lock (M12) Single Keyway Field Attachable Connectors	<u>120085</u>
GWconnect Heavy-Duty Connectors and Accessories	<u>93601</u>

This document was generated on Mar 25, 2024