



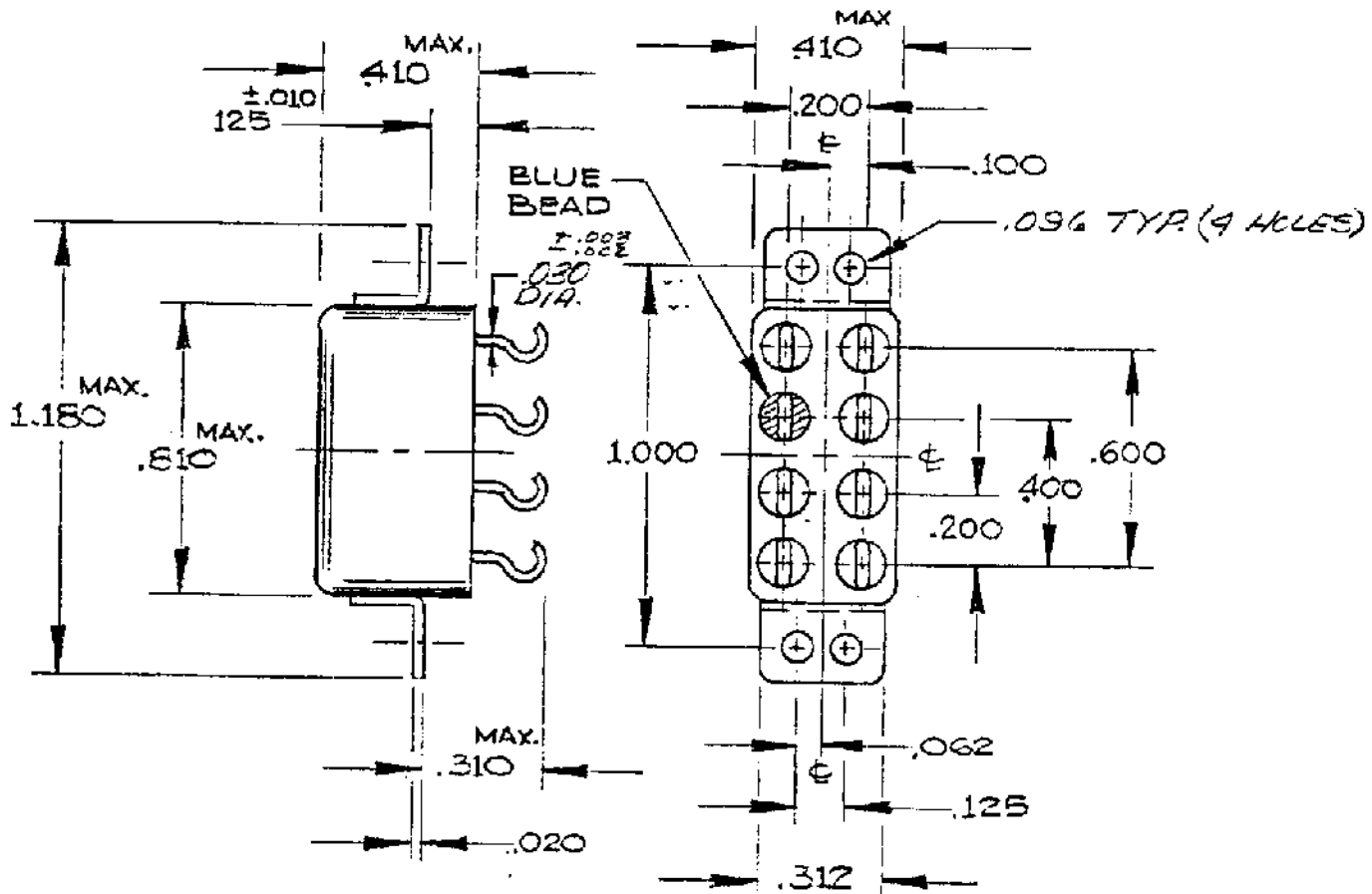

CUSTOMER DATA SHEET

TOLERANCE UNLESS OTHERWISE SPECIFIED
DECIMALS $\pm .005$ FRACTIONAL $\pm 1/64$

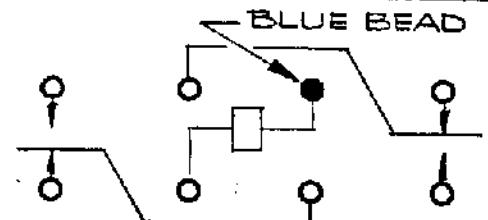

CONTACT RATING:
2A @ 28VDC RES. 100,000 OPERATIONS
10mA @ 30mV RES. 100,000 OPERATIONS

DR. 3-22-79 CK. J A L

Communications Instruments, Inc.

COIL: @ 25°C

WINDING # 1

700 OHMS $\pm 10\%$

13.5 VDC MUST OPERATE

1.5 VDC MUST RELEASE

WINDING # 2

OHMS

MUST OPERATE

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE - 65 °C TO + 125 °C

NOTES: NOMINAL VOLTAGE 26.5VDC

CUST. QPL
CUST. NO. H39016/6-128L

TYPE "HFW" RELAY

HFW 1106 K12