

MHM500-00A


In Production

RoHS

REACH



Appearance & Shape

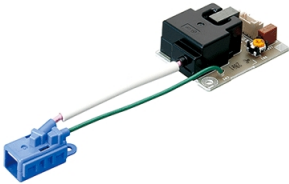

Packaging Information

Packaging	Specifications	Standard Packing Quantity
-	Carton Box	200

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

MHM500-00A



Specifications

Input Voltage	12.0Vdc
Consumption Electricity	2W
Operating Temperature Range	-10°C to 50°C
Operating Humidity Range	20%RH to 80%RH
Ozone Amount	1.1mg/H typ
Max Operating Duty (%)	30(3S≥On time≥0.2S)
External ON/OFF(Remote)	✓
Lead Length	68mm
state monitoring(Vmon)	✓

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.