

H0,75/14D ZH GR SV


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

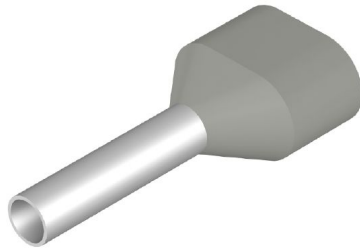

- in multipack bag (5 x 100 pcs.)
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Twin wire-end ferrule, 11 mm, 8 mm, grey
Order No.	9018520000
Type	H0,75/14D ZH GR SV
GTIN (EAN)	4008190097998
Qty.	500 ST
Packaging	Multipack bag

H0,75/14D ZH GR SV

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

Dimensions and weights

Net weight 0.14 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Technical data

Description of article	Twin wire end ferrule, grey	Version	Twin wire-end ferrule
------------------------	-----------------------------	---------	-----------------------

Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	8 mm
Collar width (B)	3 mm	Collar height (A)	5.5 mm
Plastic collar thickness (S2)	0.3 mm	L1 in mm	14.00 mm
Wire connection cross section AWG, max.	AWG 18	Metal sleeve thickness (S1)	0.15 mm
Stripping length	11 mm	Conductor cross-section	0.75 mm ²
Colour code	DIN		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01
ECLASS 13.0	27-40-02-01	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

