


T1024NSE7MQPA (Active)

QorIQ, 2xCPU 64-Bit Pwr Arch, 1.2GHz, DDR3L/4, PCIe, 1/10GbE,HW Accel,SEC,0 to 105C,DeepSleep,23x23

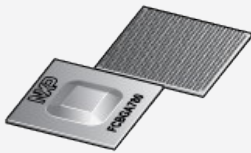

Package :
FBGA780

FBGA780, plastic, fine-pitch ball grid array; 780 bumps; 0.8 mm pitch; 23 mm x 23 mm x 1.92 mm body

Buy Options

Operating Characteristics

Environmental Information

Quality Information

Shipping Information

Buy Options

T1024NSE7MQPAActiveTRAY-Tray, Bakeable, Multiple in Drypack

Distributor

935311888557

Min. Package Quantity: 60

Lead Time: 16 weeks

Operating Characteristics

Parameter	Value
Description	QorIQ, 2xCPU 64-Bit Pwr Arch, 1.2GHz, DDR3L/4, PCIe, 1/10GbE,HW Accel,SEC,0 to 105C,DeepSleep,23x23

Environmental Information

Material Declaration	PbFree	EU RoHS	Halogen Free	RHF Indicator	2nd Level Interconnect	REACH SVHC	Weight (mg)
T1024NSE7MQPA (935311888557)	Yes	Yes Certificate Of Analysis (CoA)	Yes	D	e1	REACH SVHC	1542.9

Quality Information

Material Declaration	Safe Assure Functional Safety	Moisture Sensitivity Level (MSL)	Peak Package Body Temperature (PPT) (C°)	Maximum Time at Peak Temperatures (s)
		Lead Free Soldering	Lead Free Soldering	Lead Free Soldering
T1024NSE7MQPA (935311888557)	No	3	250	30

Shipping Information

Part Number	Harmonized Tariff (US) Disclaimer	Export Control Classification Number (US)	CCATS
T1024NSE7MQPA (935311888557)	854231	5A002A1	G143809

