

Actuator

61-
3440.4/8



<https://eao.com/p/61-3440.4/8>

Your product:



61-3440.4/8 Actuator

MOUNTING

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Grey

Lens material: Plastic

Lens illumination: non illuminative

Lens shape: mushroom-head

Lens optics: opaque

MECHANICAL CHARACTERISTIC

Switching action: Maintained

Tightening torque: Max. 0.5 Nm

Weight: 0.02 kg

AMBIENT CONDITION

Operating temperature: – 25 °C ... + 55 °C


CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER


Short Description:	Actuator, mushroom-head, non illuminative, Grey, Plastic, opaque, Maintained
Housing colour:	Grey
Housing material:	Plastic
Marking:	Arrows
Product attributes:	Twist to unlock clockwise
Wiring diagrams:	

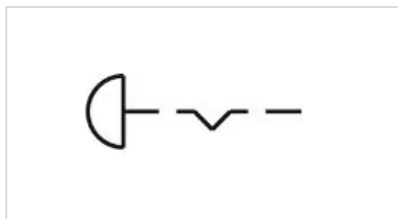

Mounting cut-outs:

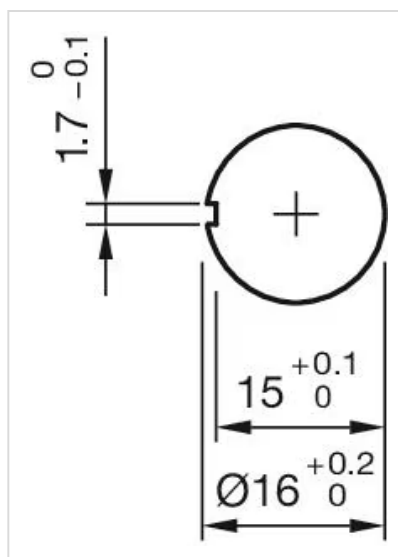

Dimension drawings:

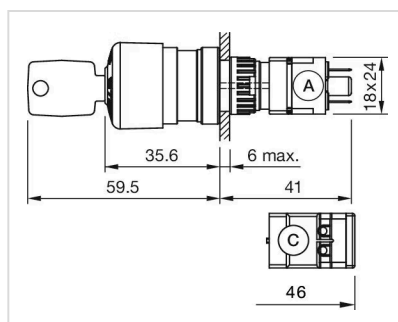

A = Plug-in terminal 2.8 mm x 0.5 mm
C = Screw terminal