



Connect to the future

Service cordons
BP 30 Rue Velpeau
37110 CHATEAU-RENAULT

FICHE TECHNIQUE CORDON

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER : **R285.426.000**

Issue : **00**


Date : **01/06/04**

Customer : **FARNELL UK**

Specification : **NA**

Edition / Issue : - **NA** Date : **NA**

All dimensions are in mm

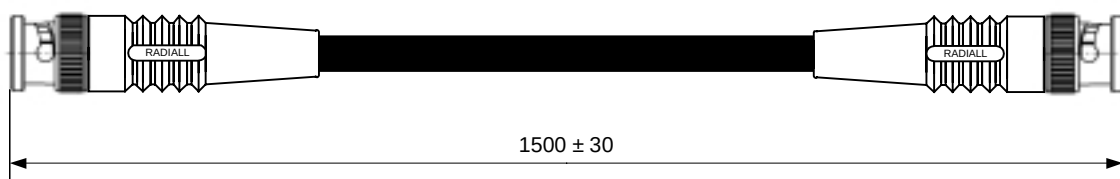

Connectors designation :

Connector 1 : **BNC straight plug crimp type
(R141.082.161)**
Torque Wrench : **NA**

Connector 2 : **BNC straight plug crimp type
(R141.082.161)**
Torque Wrench : **NA**

Cable designation :

KX15 (C291.305.010)

Cable colour :

Black

Outer diameter :

4.95mm

Marking:

NA

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : **50Ω**

Frequency range : **DC-1GHz**

Insertion Loss : **NA**

Return Loss. : **NA**

Low Frequency

Insulation Resistance : **5000 Mohms mini**

Voltage Rating : **500 Vrms maxi**

CUSTOMER'S APPROVAL

Service or
Company's stamp

Name
Date

MECHANICAL CHARACTERISTICS :

Static bending radius : **20mm**

Cable crush resistance : **NA**

Life (connectors) : **100 matings**

ENVIRONMENTAL CHARACTERISTICS :

Temperature range : **-35°C/+70°C**

J.MOLLES	04/23	01/06/04	Création / First Issue	O. LE FOULER	1/1
Nom / Name	Edition / Issue	Date	Modification	Vérifié par / Checked by	