


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1451320303](#)
Status: **Active**
Overview: [Micro-Fit Connector System](#)
Description: Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assembly, Single Row, 300.00mm Length, 3 Circuits, Black

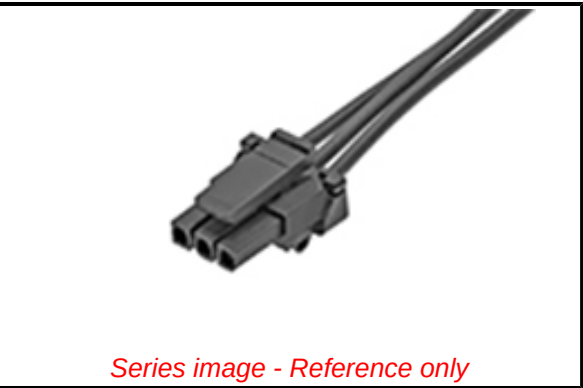

Series image - Reference only

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[3D Model \(PDF\)](#)
[Datasheet \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Cable Assemblies
Series [145132](#)
Application Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration Dual Ended Connectors
Connector to Connector Micro-Fit TPA Both Ends
Overmolded No
Overview [Micro-Fit Connector System](#)
Product Name Micro-Fit TPA
Type Discrete Wire Assembly
UPC 191130115617

Physical
Cable Length 300.00mm
Circuits (Loaded) 3
Color - Resin Black
Gender Female-Female
Lock to Mating Part Yes
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 7.649/g
Number of Rows 1
Packaging Type Bag
Pitch - Mating Interface 3.00mm
Plating min - Mating 1.016µm
Plating min - Termination 1.016µm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.85mm
Wire Size AWG 20
Wire/Cable Type UL 1061

Electrical
Current - Maximum per Contact 8.5A
Voltage - Maximum 300V AC/DC

Material Info

Reference - Drawing Numbers
Sales Drawing 4000095240-000

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[145132](#) Series

Mates With
Micro-Fit 3.0 Plug Housing [43640](#)

Micro-Fit TPA Plug Housing [200875](#)

Micro-Fit 3.0 Header [43650](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION