




**Part Number :** [522712469](#)

**Product Description :** Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 24 Circuits, Gold Plating

**Series Number :** 52271

**Status :** Active

**Product Category :** FFC / FPC Connectors

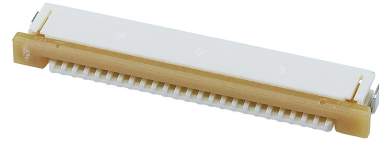

---

## Documents & Resources

### Drawings

[Drawing 522712469\\_sd.pdf](#)

### 3D Models and Design Files

[3D Model 522712469\\_stp.zip](#)

### Specifications

[Application Specification AS-52271-001-001.pdf](#)


[Packaging Specification SPK-52271-002-001.pdf](#)

[Product Specification PS-52271-054-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

### [Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

### [Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

---

## Part Details

### General

Status	Active
Category	FFC / FPC Connectors
Series	52271
Description	Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 24 Circuits, Gold Plating
Series Name	Slider
Product Family	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	822350052597

### Agency

CSA	LR19980
UL	E29179

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

### Physical

Actuator Type	Slider
Circuits (Loaded)	24
Circuits (maximum)	24
Color - Resin	Natural
Contact Position	Bottom
Durability (mating cycles max)	30

Flammability	94V-0
Mated Height	3.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	988.748/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	1.00mm
Pitch - Termination Interface	1.00mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
1.00mm Pitch Premo-Flex FFC Jumpers	<u>15039</u>

---

This document was generated on Sep 25, 2024