


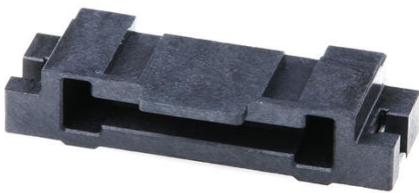

Part Number : [5051470490](#)
Product Description : 2.00mm Pitch Easy-On Flexi-Latch FPC-to-Board Connector, Right-Angle, Surface Mount, Positive Inertia Lock, 4 Circuits
Series Number : 505147
Status : Active
Product Category : FFC / FPC Connectors



Documents & Resources

Drawings

[5051470490_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

Specifications

[5051479200-200.pdf](#)

[5051470000-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS

- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	505147
Description	2.00mm Pitch Easy-On Flexi-Latch FPC-to-Board Connector, Right-Angle, Surface Mount, Positive Inertia Lock, 4 Circuits
Product Name	Easy-On
UPC	887191676302

Agency

UL	E29179
----	--------

Electrical

Current - Maximum per Contact	2.0A
Voltage - Maximum	125V

Physical

Actuator Type	Flexi-Latch
Circuits (Loaded)	4
Color - Resin	Black
Contact Position	Bottom

Durability (mating cycles max)	25
Flammability	94V-0
Mated Height	4.85mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	528.169/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	2.00mm
Plating min - Mating	0.102µm
Plating min - Termination	0.051µm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C
Wire/Cable Type	FPC only

Mates With / Use With

Mates with Part(s)

Description	Part Number
2.00mm Pitch Easy-On Flexi-Latch FPC-to-Board Plug Jacket, 4 Circuits	<u>5051480408</u>

This document was generated on Sep 20, 2025