



Quality Products. Service Excellence.

Horizontal Finger Cable Manager RB-HFM Series

TOP SELLER



Features:

- The rear manager body is constructed in 16-gauge steel.
- The fingers and cover clips are constructed in black UL94V-0 Polycarbonate.
- The included removable cover is constructed in aluminum.
- Includes cutouts at the rear for cable pass-through.
- Fits standard EIA-compliant mounting rails.
- Metal components finished in textured RAL9005 black powder paint.
- Requires mounting hardware.
- Finished in textured RAL9005 black powder paint finish.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS and REACH compliant.
- Manufactured in North America.

RACK BASICS®

A HAMMOND BRAND



For a double-sided manager, install two (2) managers mounted back-to-back. The rear opening provides a cable pass-thru.




Part of the Rack Basics® line of value rack solutions.

Gallery



Accessories

- Hardware for Rack Mounting Solutions
- Hook and Loop Convenience Roll

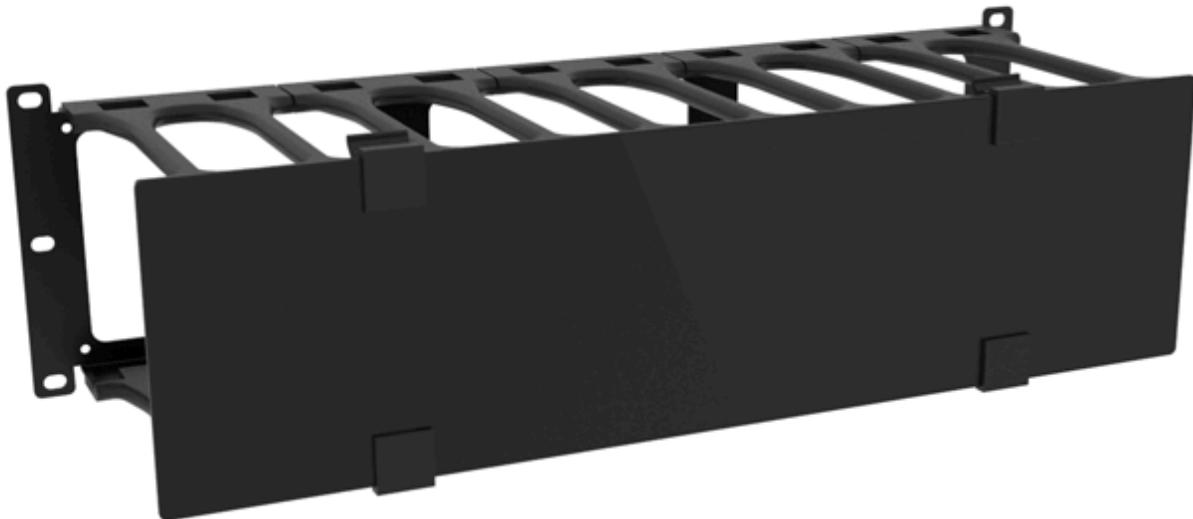

Front Only	Overall Dimensions			Usable Mounting Dimensions		
	Part No.	Height	Width	Depth	Rack Units	Height
RB-HFMS1		1.47	19.00	4.81	1U	1.75
RB-HFMD1		1.47	19.00	6.54	1U	1.75
RB-HFMS2		3.22	19.00	4.81	2U	3.50
RB-HFMD2		3.22	19.00	6.54	2U	3.50
RB-HFMS3		5.22	19.00	4.81	3U	5.25
RB-HFMD3		5.22	19.00	6.54	3U	5.25
RB-HFMS4		6.97	19.00	4.81	4U	7.00
RB-HFMD4		6.97	19.00	6.54	4U	7.00

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.