

MTCA-085-02-S-DV-SMT-K-TR

MTCA SERIES

(0.75 mm) .030"

MICRO TCA CONNECTOR

SPECIFICATIONS

For complete specifications see www.samtec.com?MTCA

Insulator Material: LCP

Terminal Material: Brass Alloy

Plating: Au or Sn over

50 μ" (1.27 μm) Ni

Operating Temp Range: -55 °C to +125 °C


RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality




Mates with:
(1.60 mm) .062" thick cards

APPLICATION

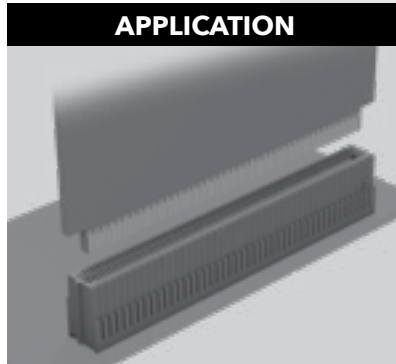

Contacts on (0.75 mm) .030" pitch



Supports hot plugging and high-speed serial connections

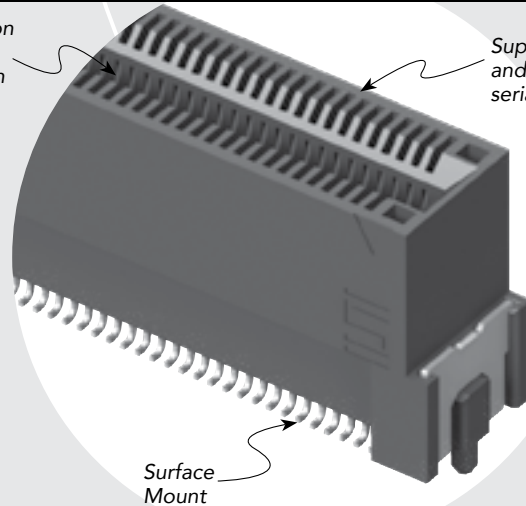

Surface Mount

ALSO AVAILABLE (MOQ Required)

- Additional positions

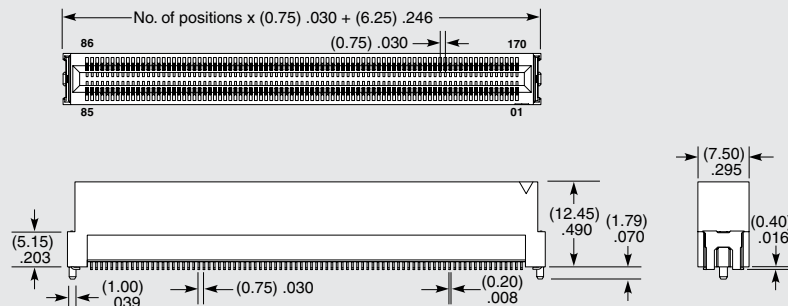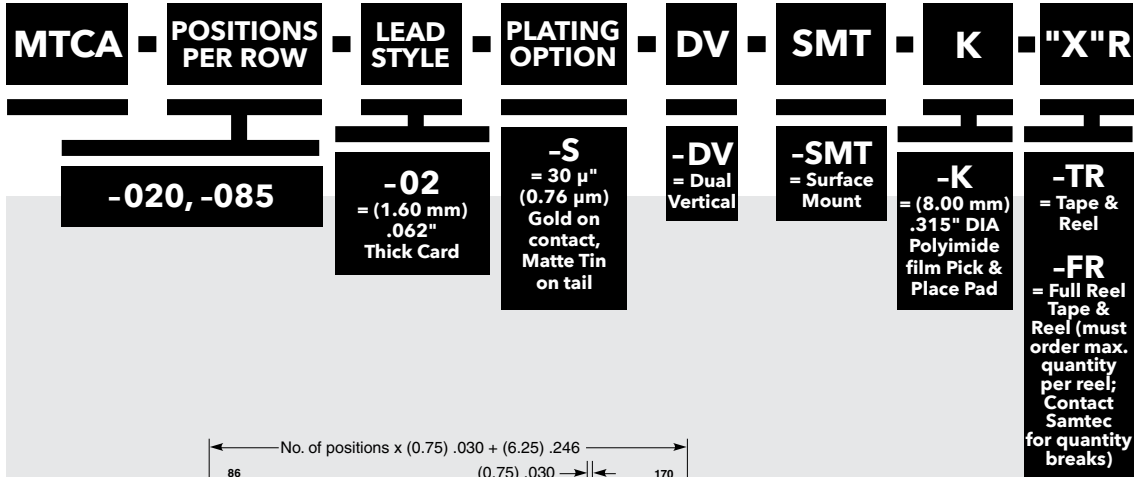

Note: Some sizes, styles and options are non-standard, non-returnable.