

BBGK00160808301Y00

Search by :

- Part Number
- Characteristics
- Cross reference




MP ?

For General Signal Line
Under 1GHz

- Series Pdf
- ICP Report
- RoHSREACHCoC

Product detail	
L (mm) ±	1.60±0.15
W(mm) ±	0.80±0.15
T (mm) ±	0.80±0.15
Size Code (JIS/EIA)	1608/0603
RDC(Ω)Max	0.25
Rated Current(mA)	500
Rated Current(mA)Max	500
Impedance Ω(at 100MHz)	300
Tolerance(±%)	25
Test Frequency	100 MHZ,200 mV

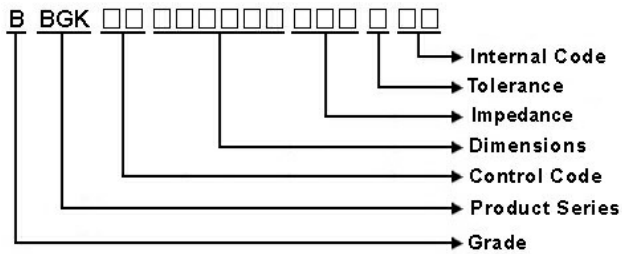

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

News

- Media Center
- New Products
- Events
- Product Notices

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.