

PRODUCT NUMBER


71961-0XXLF

INDICATES THE PRODUCT IS RoHS
COMPATIBLE, SEE NOTE 2

NUMBER OF POSITIONS	SIZE	DIM "C"	DIM "J" MAX
04	2x 2	6.54	20.46
06	2x 3	9.08	23.00
08	2x 4	11.62	25.54
10	2x 5	14.16	28.08
14	2x 7	19.24	33.16
16	2x 8	21.78	35.70
18	2x 9	24.32	38.24
20	2x10	26.86	40.78
26	2x13	34.48	48.40
30	2x15	39.56	53.48
34	2x17	44.64	58.56
40	2x20	52.26	66.18
44	2x22	57.34	71.26
50	2x25	64.96	78.88
60	2x30	77.66	91.58
64	2x32	82.74	96.66

EXTENDED RANGE

- TOOLING FEASIBILITY CONFIRMED
- SAMPLES ON DEMAND
- AVAILABILITY ON DEMAND

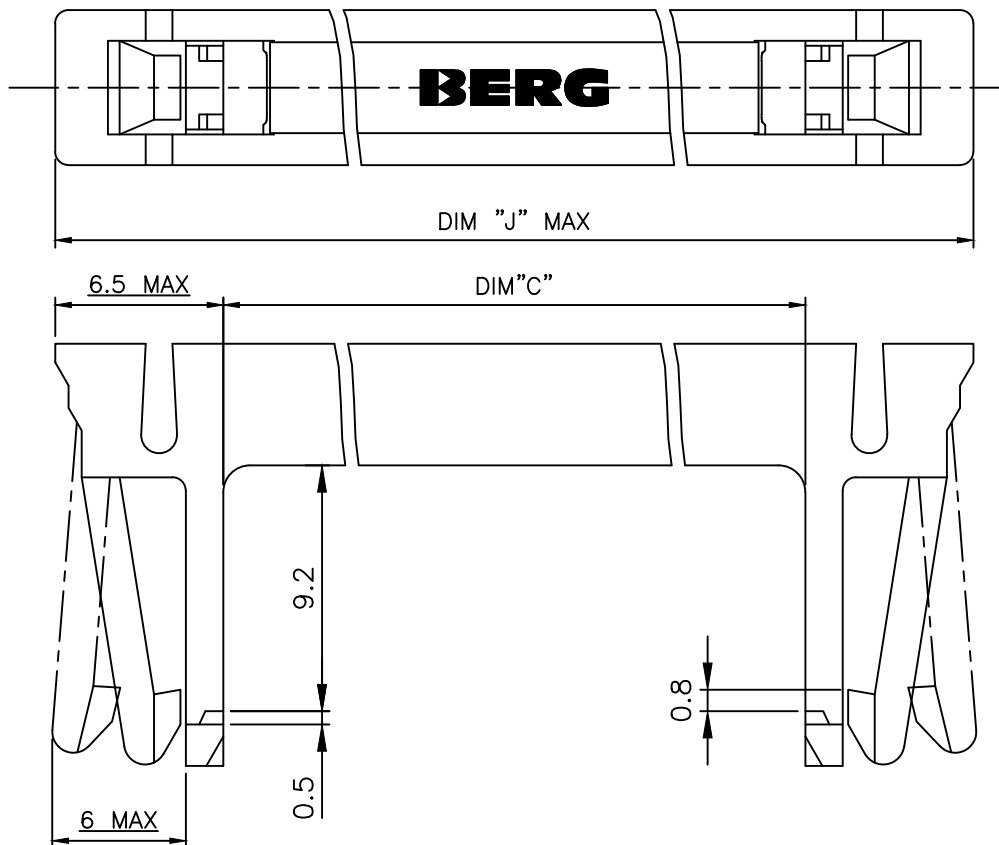

NOTES:

- MOLDING MATERIAL UNFILLED POLYESTER
FLAME RETARDANT PER UL-94-V0
COLOR GREY
- RoHS COMPATIBLE PRODUCT
 - LABELLING:
- MEETS PACKAGING SPECS AS PER GS-14-920
 - LEGAL STATEMENT: SEE GS-22-008
 - THE PRODUCT IS NOT INTENDED TO BE EXPOSED
TO MANUFACTURING SOLDER PROCESS
 - PRODUCT MEETS WITH EU 2002/EG/95
- THIS PART SERIES IS NOT INITIALLY INTENDED FOR
AUTOMOTIVE APPLICATIONS. ADDITIONAL FEES ARE
CHARGEABLE FOR ANY ADDITIONAL QUALIFICATION AND
TEST REPORTS PERFORMED OUTSIDE THE SCOPE OF THE
STANDARD PRODUCT SPECIFICATIONS.
- UNLESS OTHERWISE APPROVED BY AMPHENOL, ALL PARTS
AND COMPONENTS ARE DESIGNED & BUILT ACCORDING TO
AMPHENOL'S SPECIFICATIONS WHICH ARE SUBJECT TO
CHANGE WITHOUT NOTICE.

mat'l. code SEE NOTE 1				surface ISO 1302 ✓	tolerance ISO 406 ISO 1101	projection mm	product family EURO QUICKIE FEMALE
ltr	ecp no	dr	date	tolerances unless otherwise specified	linear	mm	title
E	F20358	GQU	02.06.19	angles	.x ± 0.3		STRAIN RELIEF
F	F05-0255	LMU	05.10.11		.xx ± 0.15		LATCHING
G	F06-0270	LMU	06.09.12		.xxx ± 0.05	scale 1:1	
H	F06-0274	LMU	06.09.25	dr	L.MULIN 05.10.11		dwg no
J	F-54577	DDE	25.02.10	engr	J.COMPAGNON 05.10.11		sheet 1 of 1
				chr			size
				appd	J.COMPAGNON 05.10.11		A3
sheet index	revision sheet						type
							CUSTOMER Drawing

STATUS:Released Printed: Feb 11, 2025