


BR1632A

BR Coin-type Lithium Battery for high temperature

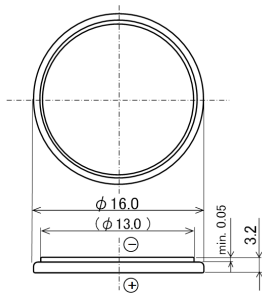

* () is for reference purpose only
This drawing is a schematic diagram
showing the dimensions.
The dimensional ratio is different from the
actual battery.

Features & Benefits

- In addition to the appeal of our BR series coin-type lithium batteries, poly-carbonmonofluoride cells can operate in the temperatures up to 125°C

Specifications

Nominal voltage		3V
Nominal capacity		120mAh
Continuous drain		0.03mA
Dimensions* 1	Diameter(Max.)	16.0mm
	Height(Max.)	3.2mm
Weight*1		Approx. 1.5g
Operating temperature		-40°C to +125°C

*1 Without tabs.

Applications

Automotive electronic components(TPMS, ETC), hot water and electricity meters, memory backup(host computers, FA equipment), etc.

Discharge temperature characteristics

