


2-828431-1 Product Details

 Share  Print  Email



 Active

 View 3D PDF

.100 inch AMPMODU Headers

2X21P MOD2 STIFTL

2-828431-1 

TE Internal Number: 2-828431-1

Product Highlights [View All](#)

- Connector
- Header Type = Breakaway
- 42 Positions
- Mating Post Length = 5.90 mm
- Row-to-Row Spacing = 2.54 mm

Pricing & Availability

Request Sample





Add to My Part List

Buy Product through  
Distributor


Feedback

Documents **Features** Compliance

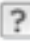


Please Note:  
Use the Product Drawing for all design activity

Product Type Features	
Product Type	Connector
Mount Angle 	Right Angle
PCB Mount Retention 	Without
Board Standoff 	Without
Mating Connector Lock 	Without
Profile	Standard

Mechanical Attachment	
Mounting Ears 	Without
Panel Mount Retention 	Without




Termination Features	
Termination Post Length (mm [in]) 	3.00 [0.118]



Dimensions	
Mating Post Length (mm [in])	5.90 [0.232]


Body Features	
Header Type 	Breakaway
Row-to-Row Spacing (mm [in])	2.54 [0.100]
Selectively Loaded 	No
Mount Type 	Printed Circuit Board


Contact Features	
Contact Plating, Mating Area, Material 	Gold (.1) over Palladium Nickel
Solder Tail Contact Plating	Tin over Nickel
Contact Base Material	CuZn

Housing Features	
Housing Material	PBT
Housing Color	Green

Configuration Features	
Number of Positions 	42
Number of Rows 	2
Surface Mount Compatible 	No

Industry Standards	
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Wave solder capable to 240°C
RoHS/ELV Compliance History	Always was RoHS compliant
UL Flammability Rating	UL 94V-0

Conditions for Usage	
High Temperature Housing 	No

Operation/Application	
High Speed Serial Data Connector 	No

Other	
Brand	AMP

Related Products

Not quite the product  
you're looking for?  
[Find Similar Products](#)

[View Part in Product  
Feature Selector](#)

[Check for Tooling](#)

Corporate Information

[About TE](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)  
[Terms & Conditions](#)  
[Privacy Policy](#)  
[Global Accessibility Statement](#)

Quick Links

[Distributor Inventory](#)  
[Product Cross Reference](#)  
[Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Knowledge Base](#)  
[Manage Your Account](#)

Keep Me Informed

