

# Mini-Com™ Flush Mount Modular Patch Panels

## specifications

Flush mount modular patch panels shall consist of a metal panels with molded rear snap-in faceplates. Patch Panels shall accept all Mini Com modules for UTP, STP, fiber or A/V applications and shall mount to standard 19" racks. Patch panels shall be available in 24-port and 48-port standard density. Select styles shall be available in white. Flush mount patch panels shall be easy to identify with pre-numbered ports. Angled patch panels shall be designed at an optimum angle to help route the cable.



## technical information

|                          |                                                                                                         |
|--------------------------|---------------------------------------------------------------------------------------------------------|
| <b>Mounting options:</b> | Mounts to standard 19" rack                                                                             |
| <b>Material:</b>         | Stamping is CRS and faceplate is ABS                                                                    |
| <b>Packaging:</b>        | Packaged with appropriate pre-installed snap in faceplates and a set of mounting screws (#12-24 and M6) |

## key features and benefits

|                                      |                                                                                                                                                                   |
|--------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <b>Modular</b>                       | Accepts all Panduit Mini-Com™ Modules to mix and match media types in the same panel                                                                              |
| <b>Angled design</b>                 | Minimize the need for horizontal cable managers by enabling patch cords to be routed directly into vertical cable managers which leads to increase closet density |
| <b>Port and panel identification</b> | Pre-numbered ports with write on areas                                                                                                                            |
| <b>Optional strain relief bars</b>   | To help support and manage cables                                                                                                                                 |
| <b>Optional filler panels</b>        | Flat and angled design fill unused rack openings to provide a clean and consistent look when used with any version of Panduit patch panels                        |
| <b>Optional extender bracket</b>     | Allows 19" patch panels to be mounted on a 23" rack                                                                                                               |
| <b>Color options</b>                 | Select styles available in white, standard color is black                                                                                                         |

## applications

Mini-Com™ Flush Mount Modular Patch Panels are ideal for multi-media applications; they accept all Mini-Com™ Modules. Flat and angled designs in various port densities available to fit most needs, include pre-numbered port identification. Angled patch panels are available for applications in which rack space

is limited. The design allows cable to flow to each side of the rack, minimizing the need for horizontal cable managers and increasing the density of the rack space. Flush mount patch panels can mount on a standard 19" rack or a 23" rack when using the extender brackets PEB1 or PEB2.

### Mini-Com™ Flat Flush Mount Patch Panels (ports grouped in 4)

24-port, 1 RU: CPP24FMWBLY  
48-port, 2 RU: CPP48FMWBLY  
48-port, 2 RU (vertical numbering): CPP48FMVNSWBLY

### Mini-Com™ Angled Flush Mount Patch Panels (ports grouped in 4)

24-port, 1 RU: CPPA24FMWBLY  
48-port, 2 RU: CPPA48FMWBLY

### Mini-Com™ Flat Flush mount patch panels (ports grouped in 6)

48-port, 2 RU: CPP48FM6BL  
48-port, 2 RU (vertical numbering): CPP48FM6VNSBL

### Mini Com™ Angled Flush mount patch panels (ports grouped in 6)

48-port, 2 RU: CPPA48FM6BL  
48-port, 2 RU (vertical numbering): CPPA48FM6VNSBL

### Mini-Com Flush Mount Patch Panels (White)

24-port, 1 RU: CPP24FMWWH  
48-port, 2 RU: CPP48FMWWH  
24-port angled, 1 RU: CPPA24FMWWH  
48-port angled, 2 RU: CPPA48FMWWH

### Patch Panel Accessories

**Transitional cover:** CPATCWH  
CPATCBL

#### Angled filler panels:

**White, angled filler panel, 1 RU:** CPAF1WH  
**White, angled filler panel, 2 RU:** CPAF2WH  
**Black, angled filler panel, 1 RU:** CPAF1BLY  
**Black, angled filler panel, 2 RU:** CPAF2BLY

#### Flat filler panels:



**White, flat filler panel, 1 RU:** DPFP1WH  
**White, flat filler panel, 2 RU:** DPFP2WH  
**Black, flat filler panel, 1 RU:** DPFP1  
**Black, flat filler panel, 2 RU:** DPFP2

### Extender Brackets




1 RU: PEB1  
2 RU: PEB2

# Mini-Com™ Flush Mount Modular Patch Panels

| Mini-Com® Flush Mount Modular Patch Panels Label Chart |            |             |             |             |
|--------------------------------------------------------|------------|-------------|-------------|-------------|
| Part Number                                            | Label Type | Laser/Ink   | LS8         | Thermal     |
| CPP24FMWBLY                                            | Adhesive   | C252X030FJJ | C252X030FJC | C252X030YPT |
| CPP24FMWWH                                             |            |             |             |             |
| CPP48FMWBLY                                            |            |             |             |             |
| CPP48FMWWH                                             |            |             |             |             |
| CPPA24FMWBLY                                           |            |             |             |             |
| CPPA24FMWWH                                            |            |             |             |             |
| CPPA48FMWBLY                                           |            | C379X030FJJ | C379X030FJC | C379X030YPT |
| CPPA48FMWWH                                            |            |             |             |             |
| CPP48FMVNSWBLY                                         |            |             |             |             |
| CPP48FM6BL                                             |            |             |             |             |
| CPP48FM6VNSBL                                          |            |             |             |             |
| CPPA48FM6BL                                            |            |             |             |             |
| CPPA48FM6VNSBL                                         |            |             |             |             |

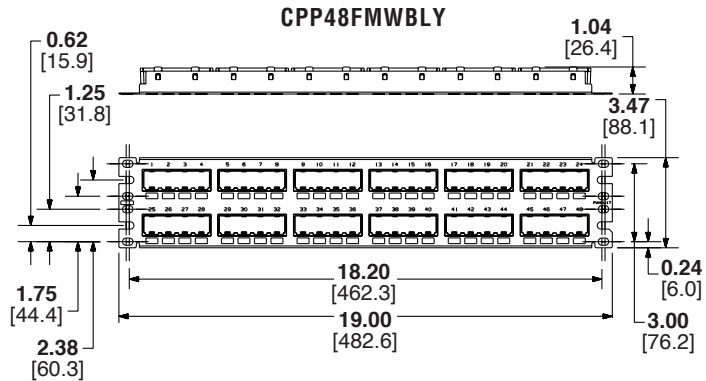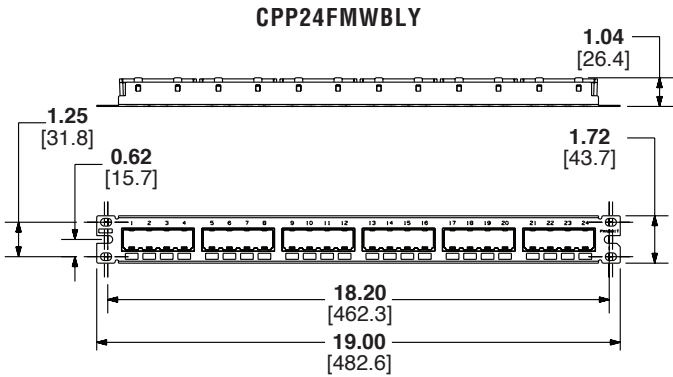


Dimensions are the same as CPP24FMWBLY

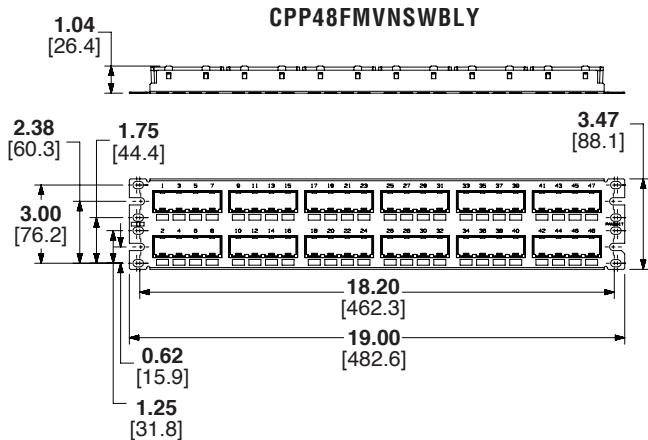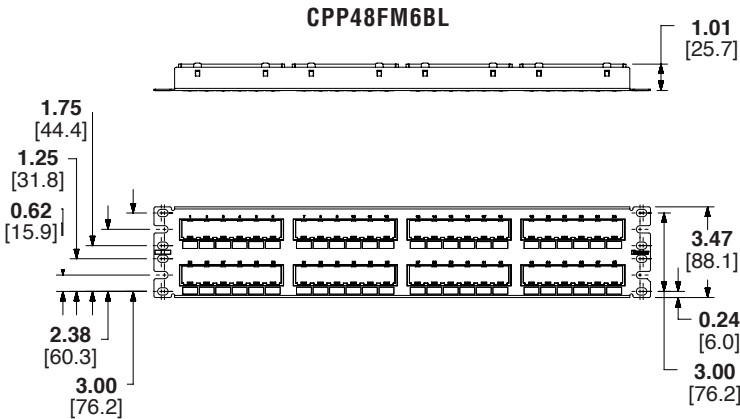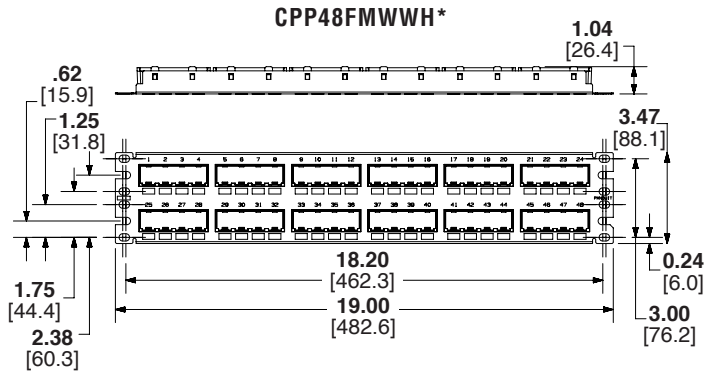


# Mini-Com™ Flush Mount Modular Patch Panels


CPP48FM6VNSBL

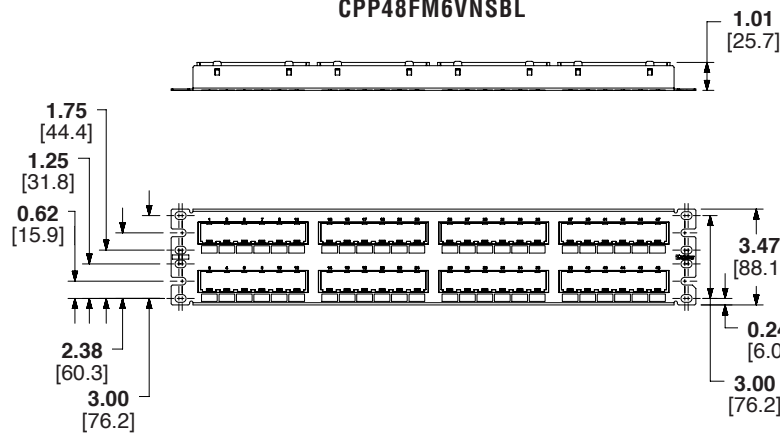


CPPA24FMWBLY  
CPPA24FMWWH\*

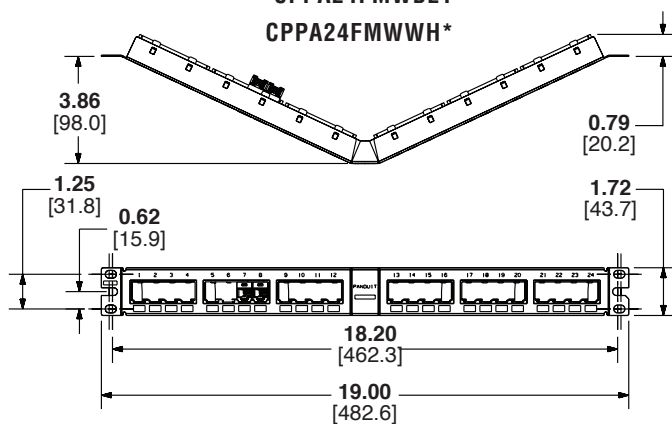


CPPA48FMWBLY  
CPPA48FMWWH\*

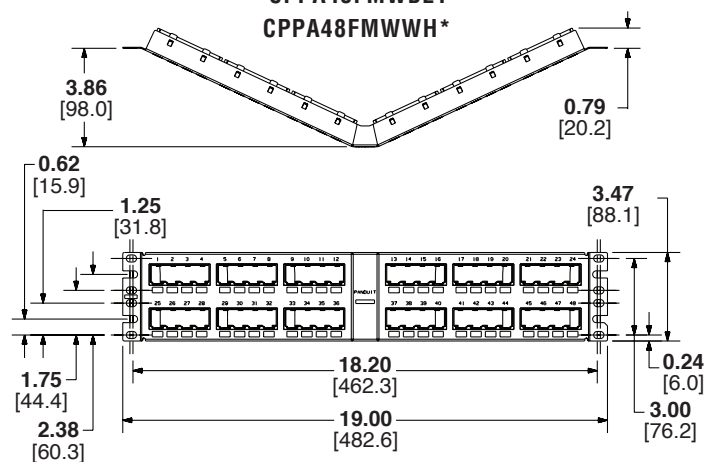

CPPA48FM6BL

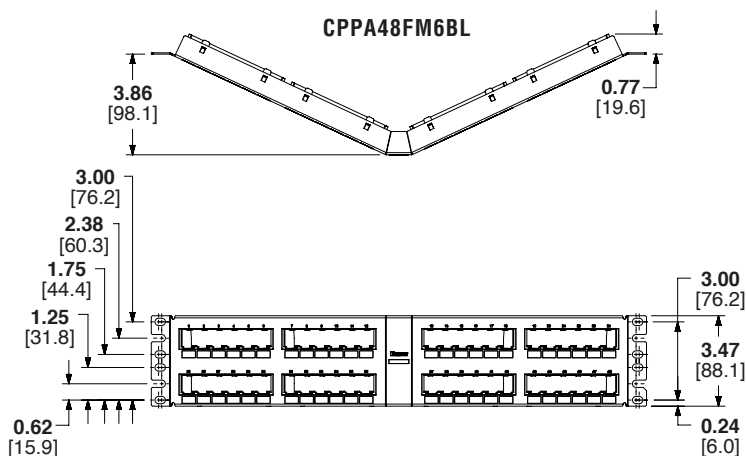

CPPA48FM6VNSBL

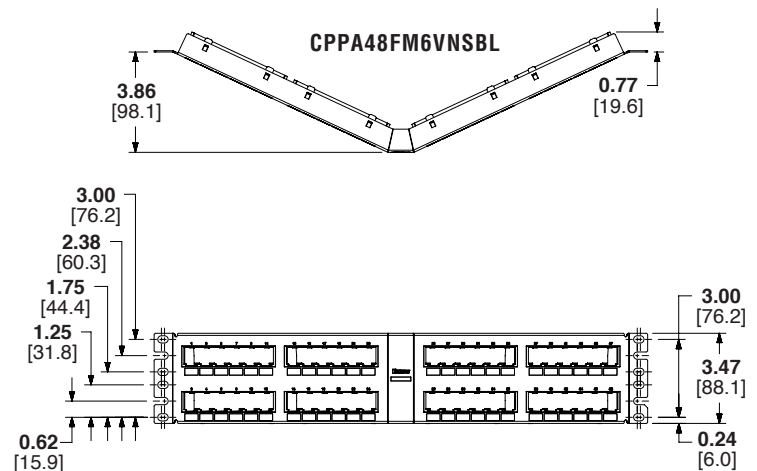

\* White patch panels do not include the write-on detail box below the ports.

Dimensions are in inches [Dimensions in brackets are metric]

## WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA  
Phone: 800.777.3300

PANDUIT EUROPE LTD.  
London, UK  
cs-emea@panduit.com  
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.  
Republic of Singapore  
cs-ap@panduit.com  
Phone: 65.6305.7575

PANDUIT JAPAN  
Tokyo, Japan  
cs-japan@panduit.com  
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA  
Guadalajara, Mexico  
cs-la@panduit.com  
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.  
Victoria, Australia  
cs-aus@panduit.com  
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to [www.panduit.com/warranty](http://www.panduit.com/warranty)

For more information

Visit us at [www.panduit.com](http://www.panduit.com)

Contact Customer Service by email: [cs@panduit.com](mailto:cs@panduit.com)  
or by phone: 800.777.3300

**PANDUIT**®

©2018 Panduit Corp.  
ALL RIGHTS RESERVED.  
OTSP33--WW-ENG  
Replaces WW-OTSP25  
2/2018