



Business Printing Simplicity

With the office printer that demands less, yet delivers more



Samsung Mono Laser Printer
ML-3710ND / ML-3750ND




Trouble-free printing

Keeping it simple, the Samsung ML-3710ND / ML-3750ND are not only incredibly easy to use, but have been designed to significantly improve paper handling reliability.

Easy to use

No need for a bulky manual with the Samsung ML-3710ND and ML-3750ND – it's so simple to use. LEDs update you on the device's status at a glance; a 2-line LCD screen* and simple navigation ensure an intuitive operation.

And managing your whole print infrastructure is easy with Samsung's range of useful software applications:

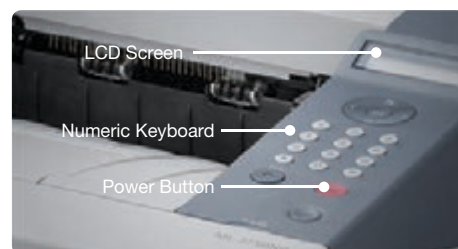

- A **Secure Pull-Printing** function is provided at no additional cost. For enabled users, documents are only released for printing when they enter their pin code at the device. This removes the issue of sensitive or confidential information being left on the printer.
- **Samsung's Barcode** printing solution integrates seamlessly into enterprise applications. Embedded barcode fonts within the device improve the efficiency of automatic data collection processes and lower associated costs.
- **Samsung's Managed Print Service CounThru™** enables you to remotely monitor activity, and calculate and manage the costs of your entire printer fleet
- **Samsung SyncThru™ Web Admin** manages networked, single and multifunction print devices. SyncThru™ Web Admin provides increased efficiency and productivity by allowing IT administrators, support staff and users to manage, monitor and diagnose multiple printing devices remotely via a familiar Web interface.
- **Easy Print Manager** enables you to locate and manage all your Samsung device and print settings from one simple location right down to ordering supplies.

1. With Optional Barcode Solution - SOL-BPSV1/SEE



- The Samsung **Universal Print Driver** facilitates quick and easy printer sharing, by enabling you to print to any Samsung device without having to install a driver for every networked printer. You can dynamically search for compatible devices on the network and check their status; enabling users to only use available printers and dramatically reduce calls to the IT helpdesk.
- **Samsung AnyWeb Print** is a handy tool that enables you to collect and only print the information you need from the web – reducing not only waste, but also time and energy too.
- **Samsung SyncThru Web Service** uses a familiar web interface to remotely manage your printer devices – enabling you to check status information, customise settings and receive email alerts all from the comfort of your desk.
- **SyncThru Admin 5** provides proactive monitoring and remote management of your printer fleet through an easy-to-use dashboard. It enables you to remotely configure and update devices, keep track of supplies, and create powerful analyses and reports.

Easy to maintain

With Samsung's Anti-Jam Technology you can feel free to get on with your work while your documents print. Unlike other models in this class, the Samsung ML-3710ND and ML-3750ND series uses a semi-retard roller which prevents unwanted situations such as misfeeds and paper jams.



Samsung semi-retard roller



Conventional friction pad



Simple economics...

With economy in mind, the Samsung ML-3710ND / ML-3750ND have been designed to make it easy to increase output while saving money.

ECO mode and result simulator



We're all aware of the need to reduce the resources we use and the impact we have on the environment, but making a difference is simple with the Samsung ML-3710ND and ML-3750ND.

Just one touch of the ECO button selects the toner save mode. And if you want to do more, Administrator can customise the ECO settings to also convert your printouts to two or four pages per sheet, as well as print in duplex as standard.

And it doesn't stop there. With the unique Result Simulator you can see exactly how much CO₂, electricity and paper you have saved with the settings you've selected. Giving you real insight into the positive impact the Samsung ML-3710ND and ML-3750ND are having on your costs and the environment too.

Worry - free printing

You'll find the ML-3710ND and ML-3750ND are so easy to use, thanks to a control panel with a numeric keypad that lets you check the status of your job.

Extra high yield toner

Print multiple page documents easily and economically with the extra high yield toner cartridges. These cartridges, which print up to 15,000 pages on the Samsung ML-3750ND and up to 10,000 pages on the Samsung 3710ND, provide a lower cost per page and require fewer replacements.



Compact and discreet

With the smallest footprint in its class, the Samsung ML-3710ND and ML-3750ND doesn't need to be pushed into the corner. In fact, at up to 20% smaller than competitor's models, and quieter with less than 51dBA**, you can give it pride of place on the desktop – and still have enough room to get your work done.



Straightforward productivity...

We believe that printers should ease workflow and boost productivity. This is why our business printers are full of features that help you to concentrate on what's important to you – rather than your printer.



Effective paper handling

Feel free to multitask while your documents print: the ML-3710ND will crank through even your biggest print jobs without relying on you for a paper refill. Upgrade the standard 250-page capacity cassette and 50-page multi-purpose tray with 520-page optional



cassettes for even larger capacity paper handling, perfect for all of your bulk printing needs. Sometimes, bigger really is better.

They say first impressions count, and you'll be able to make them last with the impressive array of media you can use with the Samsung ML-3710ND and ML-3750ND. Printing is a breeze on anything from thicker, coloured or speciality papers, to envelopes and even card stock.

And with an impressive 820 sheet total paper capacity, keeping the Samsung ML-3710ND and ML-3750ND stocked up and ready to go is simple; saving you time for the more important tasks of the day.

Effective job handling

Fast, productive output depends on processing speed, good network connectivity and adequate memory. The ML-3710ND and ML-3750ND ensure you'll never fail to be impressed; providing a dual-core processor across the range.

Offering printout speeds of up to 35ppm on the Samsung ML-3710ND and ML-3750ND, you can be sure you won't spend all your time waiting for important prints.

Plus, with enhanced expandability options, from additional memory to paper handling and connectivity options, you can broaden the capabilities of your device to suit your particular business needs.

Model	ML-3750ND Series (35ppm)	A Competitor	B Competitor
Time taken to print 50 page Microsoft PowerPoint document	1 minute 50 seconds	5 minutes 12 seconds	4 minutes 24 seconds

* Internal Benchmark Test : Tested by Samsung (14/10/10 Report by Quality Assurance Group)

ML-3710ND / ML-3750ND - Mono Printers

Simple, productive, reliable and low running costs

When you choose a printer for your business – you want to know that you're making the right choice. You want a printer that not only provides exceptional print quality – but delivers on value too. Because the Samsung ML-3710ND and ML-3750ND are so simple to use.

Simple menu structures mean that everyone can utilise all the features it has to offer. Simple paper handling means that you can print on a wide range of papers and card stock – delivering professional results every time.

Simple to use and maintain, the Samsung ML-3710ND and ML-3750ND effortlessly combines high performance with outstanding productivity and versatility. Perfect for the busy office - perfect for you.



Buyers Laboratory Inc. Test Report

ML-3710ND has been awarded the 2011 Reliability and a Highly Recommended Award for outstanding design quality, value and performance.

Product Configurations

ML-3710ND



ML-3750ND



Specifications

ML3710ND		ML3750ND	
Print			
Speed (Monochrome)	Up to 35 ppm in A4 (37 ppm in Letter)		
Resolution	Optical : 600 x 600 Enhanced : Up to 1200 dpi x 1200 dpi effective output		
First Print Out Time (Monochrome)	As fast as 6.5 seconds		
Emulation	PostScript3, PCL6/5e, IBM ProPrinter, EPSON		
Duplex	Built-in		
Paper Handling			
Standard Capacity	250-sheet Cassette, 50-sheet Multi Purpose Tray (Max 820 Sheets)		
Max. Capacity	820 Sheets		
Media Size	76 x 127 mm (3" x 5") ~ 216 x 356 mm (8.5" x 14")		
Media Type	Plain, Thin, Thick, Thicker, Cotton, Coloured, Envelope, Transparency, Pre-Printed, Recycled, Labels, Bond, Card stock, Archive		
General			
Processor	Samsung 600 MHz		Samsung 533 MHz
Memory/Storage	128 MB (Max. 348MB)		128 MB (Max. 512MB)
OS Compatibility	Windows 2000/XP(32/64bits)/Vista(32/64bits)/2003 Server(32/64bits)/ 2008 Server(32/64bits)/7(32/64bits)/2008 Server R2(64bits) Various Linux OS: RedHat Enterprise Linux WS 4, 5 (32/64 bit) Fedora 4, 5, 6, 7, 8, 9, 10, 11, 12 (32/64 bit) SuSE Linux 10.0, 10.1 (32 bit) OpenSUSE 10.2, 10.3, 11.0, 11.1, 11.2 (32/64 bit) Mandriva 2005, 2006, 2007, 2008, 2009, 2009.1 (32/64 bit) Ubuntu 5.04, 5.10, 6.06, 6.10, 7.04, 7.10, 8.04, 8.10, 9.04, 9.10(32/64 bit) SuSE Linux Enterprise Desktop 10, 11 (32/64 bit), Debian 4.0, 5.0 (32/64 bit) Mac OS 10.3 ~ 10.6, UNIX OS: Sun Solaris 9,10 (x86, SPARC) HP-UX 11.0, 11i v1, 11i v2, 11i v3 (PA-RISC, Itanium), IBM AIX 5.1, 5.2, 5.3, 5.4		
Interface	Hi-Speed USB 2.0, Ethernet 10/100/1000 Base TX		Ethernet 10/100/1000 Base TX High Speed USB 2.0
Noise Level	Less than 52dBA (Printing), Background Noise Only (Less than 26 dBA) (Standby)		
Duty Cycle, Monthly	80,000 sheets		
Dimension (WxDxH)	366 x 368 x 252.9 mm		
Weight	9.95Kg		10.09KG
Power Consumption	3.5W/60W/600W		1.4W/60W/600W

Consumables		
Yield	Standard: Average Cartridge Yield 2K standard pages. High Yield: Average cartridge Yield 5K standard pages. Extra High Yield: Average cartridge Yield 10K standard pages. (Ships with 5,000 pages Starter Toner Cartridge) Declared cartridge yield in accordance with ISO/IEC 19752.	High Yield: Average cartridge Yield 15K standard pages. (Ships with 7,000 pages Starter Toner Cartridge) Declared cartridge yield in accordance with ISO/IEC 19752.
Type	1-piece Cartridge	Black Toner Cartridge
Codes	MLT-D205S/ELS - 2k Page Toner, MLT-D205L/ELS - 5k Page Toner, MLT-D205E/ELS - 10k Page Toner	MLT-D305L/ELS - 15k Page Toner
Options		
Options	Second Paper Cassette (520 sheets) - ML-S3710A/SEE IEEE 1284B Parallel Connector - ML-PAR100/SEE 256MB Memory upgrade - CLP-MEM202/SEE Barcode Solution - SOL-BPSV1/SEE	Second Paper Cassette (520 sheets) - ML-S3710A/SEE IEEE 1284B Parallel Connector - ML-PAR100/SEE 512MB Memory upgrade - ML-MEM307/SEE Barcode Solution - SOL-BPSV1/SEE



For more information, please visit www.samsung.com/printer

