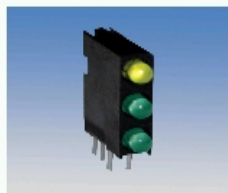


[Request more info](#)
Part Number : 5640700820F


General Description

Series	564
Configuration	3 mm Lens
Description	CBI 3MM TRI LEV Y/G Y/G Y/G
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Tri-Level Housing
Lens Style	Untinted, Diffused
Viewing Angle	60
LED Centerline	5.0mm

Absolute Maximum Ratings (Ta = 25°)

Reverse Voltage	5
Solder Temperature	260 for 5 secs
Operating Temperature	-55 to +100
Storage Temperature	-55 to +100

Operating Characteristics

Color	Green 	Yellow 
Peak Wave Length	565	585
Luminous Intensity Min	2.5	2.5
Luminous Intensity Typical	6.3	4.3
Forward Voltage Typical	2.1	2.1
Forward Voltage Max	2.8	2.8
Test Current mA	20mA	



This is a
RoHS Compliant Product
[To learn more click here](#)