

IEEE 1394 Cable 6/6

Cable for connecting IEEE 1394-compatible devices, e.g. video cameras, external CD/DVD equipment, etc.. Maximum data transfer rate 400 Mbps.
1394 connector ⇔ 1394 connector



AK-1394-10	6PIN ⇔ 6PIN, 1,0 m
AK-1394-18	6PIN ⇔ 6PIN, 1,8 m
AK-1394-30	6PIN ⇔ 6PIN, 3,0 m
AK-1394-50	6PIN ⇔ 6PIN, 5,0 m

IEEE 1394 Cable 6/4

Cable for connecting IEEE 1394-compatible devices, e.g. video cameras, external CD/DVD equipment, etc.. Maximum data transfer rate 400 Mbps.
1394 connector ⇔ 1394 mini connector



Sample only

AK-1394-104	6PIN ⇔ 4PIN, 1,0 m
AK-1394-184	6PIN ⇔ 4PIN, 1,8 m
AK-1394-304	6PIN ⇔ 4PIN, 3,0 m
AK-1394-504	6PIN ⇔ 4PIN, 5,0 m

IEEE 1394 Cable 4/4

Cable for connecting IEEE 1394 compatible devices, e.g. video cameras, external CD/DVD equipment, etc.. Maximum data transfer rate 400 Mbps.
1394 connector ⇔ 1394 mini connector




Sample only

AK-1394-1044	4PIN ⇔ 4PIN, 1,0 m
AK-1394-1844	4PIN ⇔ 4PIN, 1,8 m
AK-1394-3044	4PIN ⇔ 4PIN, 3,0 m
AK-1394-5044	4PIN ⇔ 4PIN, 5,0 m

IEEE 1394 Adaptor

AB-1394-1: 6-pin female ⇔ 4-pin male
AB-1394-2: 6-pin female ⇔ 6-pin female

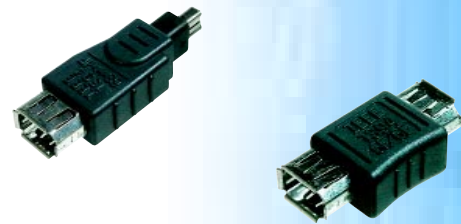

AB-1394-1	IEEE 1394 Adaptor
AB-1394-2	IEEE 1394 Adaptor

USB Adaptor

Various types, straight version, molded.



A-USB-1	USB A female ⇔ USB B female
A-USB-2	USB A female ⇔ USB B male
A-USB-3	USB A male ⇔ USB B female

USB Adaptor


Various types, angled version, molded.



A-USB-4	USB A female ⇔ USB A female
A-USB-5	USB A male ⇔ USB A male
A-USB-6	USB B male ⇔ USB B male

USB Plugs and Hoods

Plugs and hoods for self assembly of USB cables.

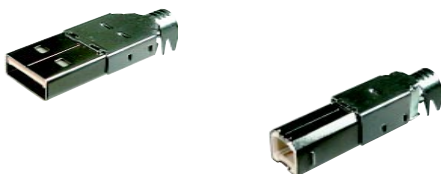

A-USBPA	USB A male, Solder Version
A-USBPB	USB B male, Solder Version
A-USBPA-HOOD	Hood for USB A male
A-USBPB-HOOD	Hood for USB B male

USB Sockets

USB sockets for PCB mounting.



A-USBSA	USB A female, PCB mounting, 90° angled
A-USBSB	USB B female, PCB mounting, 90° angled