


Current refinements (click  to remove) Search Tips

 Region  USA  Product Family  HSTTV Heat Shrink on 100 Ft. Reels  Text Search: 'HSTTV09 -C'

Your search criteria matched only one product, shown below.

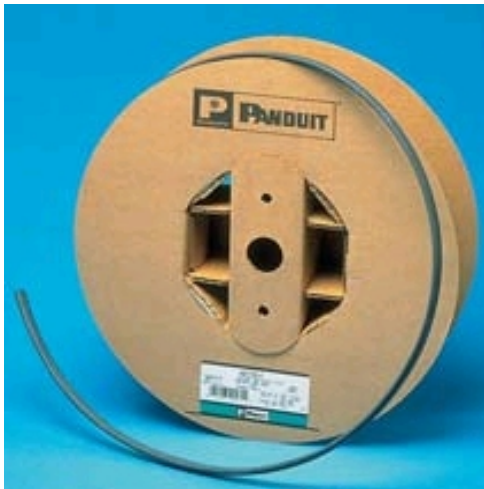

Flexible Polyolefin VW1 DRY-SHRINK™ Heat Shrink Tubing on Small Reels

- For dry locations
- Highly flame retardant
- Fast Shrink Time
- Material Type: Highly Flexible Crosslinked Polyolefin
- Shrink Ratio: 2:1
- Temperature Range:-67°F to 257°F (55°C to 125°C)
- Voltage: 600V
- UL VW-1 Recognized, CSA Certified
- Mil Spec: AMSDTL-23053/5 Class 3

Part Number:	HSTTV09C
RoHS Compliancy Status:	Compliant
Part Description:	Thin Wall Polyolefin Heat Shrink (UL224 VW1)
Material:	Polyolefin cross-linked
Color:	Black
CSA Certified:	Yes
Military Specification:	AMS-DTL-23053/5 Class 3
UL Recognized:	E122770
Length (ft.):	100
Length (m):	30.5
Flammability Rating:	UL224 VW-1
Max. Recovered I.D. (In.):	.046
Max. Recovered I.D. (mm):	1.2
Min. Expanded I.D. (In.):	.093
Min. Expanded I.D. (mm):	2.4
Nominal Diameter (In.):	3/32
Nominal Diameter (mm):	2.4
Nominal Recovered Wall Thickness (In.):	.020
Nominal Recovered Wall Thickness (mm):	.5
Shrink Ratio:	2:1
Temperature Range:	-67°F to 257°F (55°C to 135°C)
Min. Order UOM:	RL
Min. Order Qty.:	1
BOM Qty. (# of Pkgs.)	0
Add to My Catalog	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'My Catalog' features.