


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/3/30

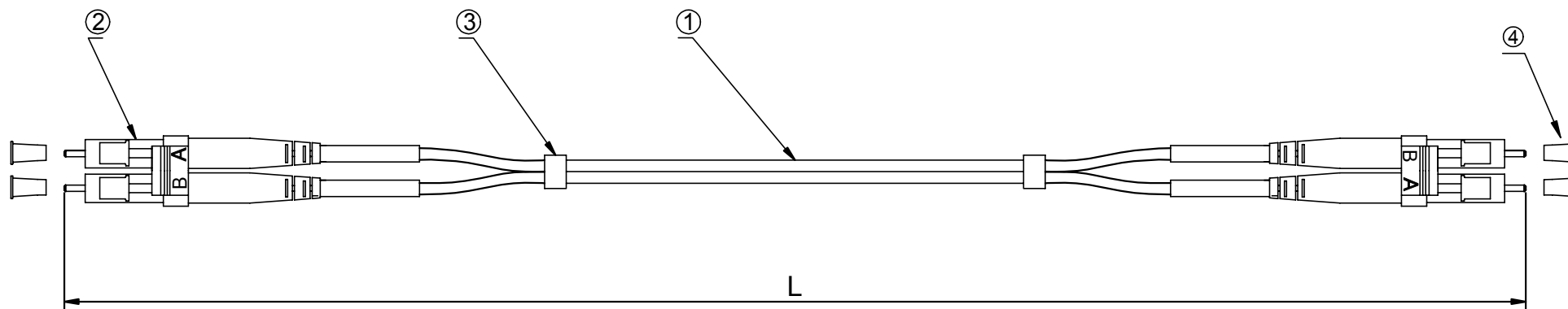

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
911S-2-5-00100-PL	671-455-A	1000±100	Yellow
911S-2-5-00200-PL	671-455-B	2000±100	Yellow
911S-2-5-00300-PL	671-455-C	3000±100	Yellow
911S-2-5-00500-PL	671-455-D	5000±100	Yellow
911S-2-5-00700-PL	671-455-E	7000±100	Yellow
911S-2-5-01000-PL	671-455-F	10000±100	Yellow
911S-2-5-01500-PL	671-455-G	15000±100	Yellow
911S-2-5-02000-PL	671-455-H	20000±100	Yellow
911S-2-5-02500-PL	671-455-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB
Return loss > 50 dB

6	
5	
4	Dust Cover
3	Shrinkage Tube
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, OFNP, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC
Industrial Cable and Connector Technology

		TITLE	Patch Cord, LC-LC,SM-9/125 G652D, Duplex, OFNP, yellow, 2.0mm, xxm			
UNIT	mm	P/N		DRAWN BY		
unless otherwise stated Tolerances mm angular XXX.XX ±0.3 ±2° XX.XX ±0.2 X.XX ±0.1		Customer P/N	911S-2-5-0xxxx-PL	CHECK BY		
		SIZE A4	SCALE Free	PAGE	1/1	APPROVAL BY