




Search within category GO

BUY NOW

DESIGN / INSTALL

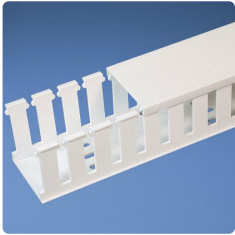

NE1.5X2WH6

Panduit® type NE halogen-free wiring duct, 1.5 W x 2 H, 6' length, halogen-free, white.

Specs	Packaging Details	Documents	★ Add to Favorites	🛒 Add to BOM
CSA Certified	Yes			
Material	Halogen-Free PPO			
Color	White			
Type	Base			
Nominal Duct Size W x H (In.)	1.50 x 2.00			
Height (In.)	2.06			
Width (In.)	1.64			
Length (ft.)	6.00			
Width (mm)	41.7			
Length (m)	1.8			
Cover Part Number	NC1.5WH6			
CE Compliant	Yes			
UL Recognized (File No. E147128)	Yes			
UL recognized continuous use temp	203°F (95°C)			
Flammability Rating	UL94V-0			
Mounting Method	Standard Mounting Holes			
Part Features	Halogen-Free Wide finger and slot design provides greater rigidity and allows use with a wide range of wire and bundle sizes. Upper and lower scorelines allows easy finger and sidewall section removals. The halogen-free material is environmentally safe and will not release corrosive or toxic gases.			
RoHS Compliancy Status	Compliant			
Min. Order Qty.	6			

On a scale of zero to 10, how likely are you to recommend Panduit to a friend, partner or colleague?

0 1 2 3 4 5 6 7 8 9 10

Not likely Most likely