




Part Number : [430610016](#)
Product Description : 3.96mm Pitch SPOX Housing,
5 Circuits, Natural
Series Number : 43061
Status : Active
Product Category : Connector Housings

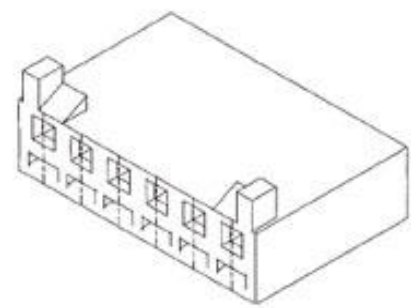

Documents and Resources

Drawings

[430610016_sd.pdf](#)

3D Models and Design Files

- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025) SCIP:839cff45-ca12-46b2-afb8-5f7ff208562e
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Housings
Series	43061
Description	3.96mm Pitch SPOX Housing, 5 Circuits, Natural
Application	Power, Wire-to-Board
Product Name	SPOX
UPC	800753843639

Agency

CSA	LR19980
UL	E29179

Physical

Circuits Detail	5
Circuits (maximum)	5
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Material - Resin	Polyester
Net Weight	1.620/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No

Pitch - Mating Interface	3.96mm
Pitch - Termination Interface	3.96mm
Stackable	No
Temperature Range - Operating	0° to +75°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mates With	3.96mm Pitch KK or SPOX headers

Use with Part(s)

Description	Part Number
SPOX Female Crimp Terminals	<u>5194</u>

This document was generated on Dec 30, 2025